


- Selon ISO 7380
- Matière : inox 302/304-A2
- 6 pans creux
- Conditionnée par lot

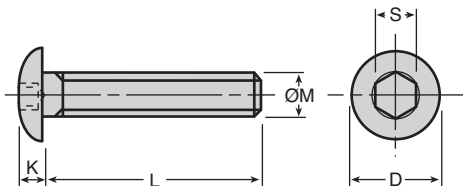

REMISES

Nb. lots	1+	6+	10+
Rem.	Prix	-5%	Sur demande

Références	Filetage øM	PAS	Longueur L	D	K	S	Quantité par lot	Prix Uni. par lot
BHC4-8/SS/B	M4	0,70	8	7,6	2,20	2,5	500	25,39 €
BHC4-10/SS/B	M4	0,70	10	7,6	2,20	2,5	500	30,44 €
BHC4-12/SS/B	M4	0,70	12	7,6	2,20	2,5	500	20,27 €
BHC4-16/SS/B	M4	0,70	16	7,6	2,20	2,5	500	28,21 €
BHC5-10/SS/B	M5	0,80	10	9,5	2,75	3,0	500	33,79 €
BHC5-12/SS/B	M5	0,80	12	9,5	2,75	3,0	500	24,57 €
BHC5-16/SS/B	M5	0,80	16	9,5	2,75	3,0	500	27,36 €
BHC5-20/SS/B	M5	0,80	20	9,5	2,75	3,0	500	55,02 €
BHC6-12/SS/B	M6	1,00	12	10,5	3,30	4,0	500	54,08 €
BHC6-16/SS/B	M6	1,00	16	10,5	3,30	4,0	500	60,84 €
BHC6-20/SS/B	M6	1,00	20	10,5	3,30	4,0	500	70,30 €
BHC6-25/SS/B	M6	1,00	25	10,5	3,30	4,0	500	49,79 €
BHC8-16/SS/B	M8	1,25	16	14,0	4,40	5,0	200	32,60 €
BHC8-20/SS/B	M8	1,25	20	14,0	4,40	5,0	200	51,60 €
BHC8-25/SS/B	M8	1,25	25	14,0	4,40	5,0	200	61,46 €
BHC8-30/SS/B	M8	1,25	30	14,0	4,40	5,0	200	57,33 €