

RAPPORT 1:1

Acier C43


- Module 1,5 à 5
- Angle de pression 20°
- Matière : acier C43
- Pour un couple, il faut deux pièces



REMISES

Qté	1+	6+	20+	40+	60+	100+
Rem. Prix	-5%	-10%	-15%	-20%	Sur demande	

Références	Dent		ØD _p	ØD _e	F	L	ØD _m	ØA	V	S	Lm	Prix Uni. 1 à 5
	Z	mod										
B1,5-16/ECO	16		24,0	26,12	6,0	18,9	20,3	8	7,10	-	12,0	14,56 €
B1,5-20/ECO	20	1,5	30,0	32,12	10,0	20,0	22,0	10	7,40	2,0	8,5	17,59 €
B1,5-25/ECO	25		37,0	39,62	10,0	23,0	28,0	10	11,09	2,0	12,0	20,97 €
B1,5-30/ECO	30		45,0	47,12	12,0	25,0	30,0	12	13,35	2,5	12,0	24,34 €
B2-16/ECO	16		32,0	34,83	8,0	23,5	25,3	8	9,50	-	14,0	17,21 €
B2-20/ECO	20	2	40,0	42,83	12,0	25,0	32,0	10	10,78	3,0	12,0	21,42 €
B2-25/ECO	25		50,0	52,82	14,0	28,0	40,0	12	14,28	3,0	12,3	34,27 €
B2-30/ECO	30		60,0	62,83	16,0	30,0	50,0	12	17,78	3,0	12,8	41,20 €
B2,5-16/ECO	16		40,0	43,53	10,0	28,1	30,3	12	11,90	-	15,0	26,15 €
B2,5-20/ECO	20	2,5	50,0	53,53	12,0	30,5	40,0	12	15,43	3,5	16,0	34,27 €
B2,5-25/ECO	25		62,5	66,00	15,0	33,5	50,0	15	19,48	3,5	16,0	41,73 €
B2,5-30/ECO	30		75,0	78,53	18,0	35,5	55,0	15	23,63	3,5	16,0	49,25 €
B3-16/ECO	16		48,0	52,25	12,0	31,7	40,3	12	14,30	-	18,0	30,62 €
B3-20/ECO	20	3	60,0	64,24	18,0	35,0	45,0	15	16,00	4,0	13,6	38,05 €
B3-25/ECO	25		75,0	79,24	20,0	38,0	55,0	15	22,00	4,0	16,0	45,93 €
B3-30/ECO	30		90,0	94,24	22,0	40,0	60,0	20	28,00	4,0	17,0	55,51 €

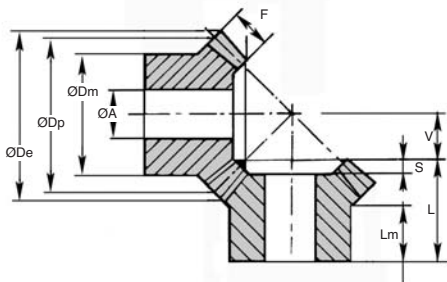

REMISES

Qté	1+	6+	20+	40+	60+	100+
Rem. Prix	-5%	-10%	-15%	-20%	Sur demande	

Références	Dent Z	mod	ØD _p	ØD _e	F	L	ØD _m	ØA	V	S	Lm	Prix Uni. 1 à 5
B3.5-16/ECO	16	3,5	56,0	60,95	14,0	36,4	45,3	16	16,60	-	20,0	34,23 €
B3.5-20/ECO	20		70,0	74,95	22,0	40,5	55,0	15	18,13	4,5	17,0	41,68 €
B3.5-25/ECO	25		87,5	92,45	26,0	43,5	65,0	20	23,97	4,5	18,0	58,47 €
B3.5-30/ECO	30		105,0	109,95	30,0	48,0	70,0	20	30,02	4,5	19,0	68,20 €
B4-16/ECO	16	4	64,0	69,65	15,0	44,3	50,3	16	19,70	-	25,0	40,14 €
B4-20/ECO	20		80,0	85,65	25,0	43,0	60,0	18	20,74	5,0	18,0	49,91 €
B4-25/ECO	25		100,0	105,65	28,0	45,0	70,0	20	28,50	5,0	18,0	63,05 €
B4-30/ECO	30		120,0	125,65	32,0	48,0	80,0	20	35,67	5,0	16,0	81,49 €
B4.5-16/ECO	16	4,5	72,0	78,38	17,5	46,3	55,3	20	21,70	-	25,0	44,38 €
B4.5-20/ECO	20		90,0	96,38	28,0	48,0	65,0	20	23,41	6,0	18,0	70,70 €
B4.5-25/ECO	25		112,5	118,80	32,0	50,0	75,0	20	31,76	6,0	18,0	85,92 €
B4.5-30/ECO	30		135,0	141,38	35,0	53,0	90,0	20	40,82	6,0	17,0	104,17 €
B5-16/ECO	16	5	80,0	87,07	18,0	48,9	60,3	20	25,10	-	25,0	48,40 €
B5-20/ECO	20		100,0	107,07	30,0	50,5	70,0	20	26,86	6,5	18,5	72,64 €
B5-25/ECO	25		125,0	132,07	34,0	53,5	90,0	20	36,36	6,5	18,0	93,46 €
B5-30/ECO	30		150,0	157,07	38,0	56,5	110,0	20	45,97	6,17	18,0	117,47 €