


- Selon ISO 4762 et DIN 912
- Matière : inox 302/304 - A2
- 6 Pans creux
- Conditionnées par lot

Utilisation

- Environnement difficile

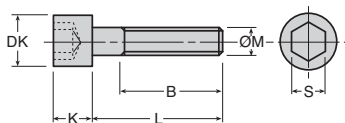

REMISES

Nb. Lots	1+	6+	10+
Rem.	Prix -5%	Sur demande	

Références	Filetage ØM	Pas	Longueur totale L	B	DK	K	S	Qté par lot	Stock*	Prix Uni. par lot
CHC1.6-5/SS/B	M1,6	0,35	5	-	3,0	1,6	1,5	200	-	66,98 €
CHC1.6-8/SS/B	M1,6	0,35	8	-	3,0	1,6	1,5	200	✓	69,69 €
CHC1.6-10/SS/B	M1,6	0,35	10	-	3,0	1,6	1,5	200	✓	78,02 €
CHC2-4/SS/B	M2	0,40	4	-	3,8	2,0	1,5	500	-	83,19 €
CHC2-5/SS/B	M2	0,40	5	-	3,8	2,0	1,5	500	✓	67,14 €
CHC2-6/SS/B	M2	0,40	6	-	3,8	2,0	1,5	500	✓	68,24 €
CHC2-8/SS/B	M2	0,40	8	-	3,8	2,0	1,5	500	✓	72,74 €
CHC2-10/SS/B	M2	0,40	10	-	3,8	2,0	1,5	500	✓	76,83 €
CHC2-12/SS/B	M2	0,40	12	-	3,8	2,0	1,5	500	✓	113,11 €
CHC2-20/SS/B	M2	0,40	20	-	3,8	2,0	1,5	500	✓	126,09 €
CHC2.5-4/SS/B	M2,5	0,45	4	-	4,5	2,5	2,0	500	-	102,98 €
CHC2.5-5/SS/B	M2,5	0,45	5	-	4,5	2,5	2,0	500	-	68,24 €
CHC2.5-6/SS/B	M2,5	0,45	6	-	4,5	2,5	2,0	500	-	76,83 €
CHC2.5-8/SS/B	M2,5	0,45	8	-	4,5	2,5	2,0	500	✓	82,06 €
CHC2.5-10/SS/B	M2,5	0,45	10	-	4,5	2,5	2,0	500	-	87,25 €
CHC2.5-16/SS/B	M2,5	0,45	16	-	4,5	2,5	2,0	500	✓	98,87 €
CHC2.5-20/SS/B	M2,5	0,45	20	-	4,5	2,5	2,0	500	✓	128,33 €
CHC3-6/SS/B	M3	0,50	6	-	5,5	3,0	2,5	1000	✓	43,70 €
CHC3-8/SS/B	M3	0,50	8	-	5,5	3,0	2,5	1000	✓	45,54 €
CHC3-10/SS/B	M3	0,50	10	-	5,5	3,0	2,5	1000	✓	47,68 €
CHC3-12/SS/B	M3	0,50	12	-	5,5	3,0	2,5	1000	✓	72,75 €
CHC3-16/SS/B	M3	0,50	16	-	5,5	3,0	2,5	1000	✓	53,81 €
CHC3-20/SS/B	M3	0,50	20	-	5,5	3,0	2,5	1000	✓	58,68 €
CHC3-25/SS/B	M3	0,50	25	18	5,5	3,0	2,5	1000	✓	106,38 €
CHC3-30/SS/B	M3	0,50	30	18	5,5	3,0	2,5	1000	✓	85,29 €
CHC3-35/SS/B	M3	0,50	35	18	5,5	3,0	2,5	500	-	102,60 €
CHC4-6/SS/B	M4	0,70	6	-	7,0	4,0	3,0	500	✓	29,06 €
CHC4-8/SS/B	M4	0,70	8	-	7,0	4,0	3,0	500	✓	21,22 €
CHC4-10/SS/B	M4	0,70	10	-	7,0	4,0	3,0	500	✓	28,10 €

*Dans la limite du disponible

Références	Filetage		Longueur totale L	B	DK	K	S	Qté par lot	Stock*	Prix Uni. par lot
	ØM	Pas								
CHC4-12/SS/B	M4	0.70	12	-	7.0	4	3	500	✓	32.08 €
CHC4-16/SS/B	M4	0.70	16	-	7.0	4	3	500	✓	21.95 €
CHC4-20/SS/B	M4	0.70	20	-	7.0	4	3	500	✓	29.56 €
CHC4-25/SS/B	M4	0.70	25	-	7.0	4	3	500	✓	33.92 €
CHC4-30/SS/B	M4	0.70	30	20	7.0	4	3	500	✓	45.48 €
CHC4-35/SS/B	M4	0.70	35	20	7.0	4	3	500	✓	39.51 €
CHC4-40/SS/B	M4	0.70	40	20	7.0	4	3	500	✓	62.96 €
CHC4-50/SS/B	M4	0.70	50	20	7.0	4	3	200	✓	30.85 €
CHC5-8/SS/B	M5	0.80	8	-	8.5	5	4	500	✓	40.50 €
CHC5-10/SS/B	M5	0.80	10	-	8.5	5	4	500	✓	35.99 €
CHC5-12/SS/B	M5	0.80	12	-	8.5	5	4	500	✓	38.20 €
CHC5-16/SS/B	M5	0.80	16	-	8.5	5	4	500	✓	43.55 €
CHC5-20/SS/B	M5	0.80	20	-	8.5	5	4	500	✓	49.98 €
CHC5-25/SS/B	M5	0.80	25	-	8.5	5	4	500	✓	48.16 €
CHC5-30/SS/B	M5	0.80	30	22	8.5	5	4	500	✓	63.42 €
CHC5-35/SS/B	M5	0.80	35	22	8.5	5	4	500	✓	61.65 €
CHC5-40/SS/B	M5	0.80	40	22	8.5	5	4	500	✓	83.01 €
CHC5-50/SS/B	M5	0.80	50	22	8.5	5	4	200	✓	43.42 €
CHC6-8/SS/B	M6	1.00	8	-	10.0	6	5	500	✓	47.36 €
CHC6-10/SS/B	M6	1.00	10	-	10.0	6	5	500	✓	54.32 €
CHC6-12/SS/B	M6	1.00	12	-	10.0	6	5	500	✓	60.37 €
CHC6-16/SS/B	M6	1.00	16	-	10.0	6	5	500	✓	66.49 €
CHC6-20/SS/B	M6	1.00	20	-	10.0	6	5	500	✓	51.58 €
CHC6-25/SS/B	M6	1.00	25	-	10.0	6	5	500	✓	60.20 €
CHC6-30/SS/B	M6	1.00	30	-	10.0	6	5	500	✓	85.08 €
CHC6-35/SS/B	M6	1.00	35	24	10.0	6	5	500	✓	54.44 €
CHC6-40/SS/B	M6	1.00	40	24	10.0	6	5	500	✓	59.28 €
CHC6-50/SS/B	M6	1.00	50	24	10.0	6	5	500	✓	144.46 €
CHC6-60/SS/B	M6	1.00	60	24	10.0	6	5	500	-	110.24 €
CHC6-70/SS/B	M6	1.00	70	24	10.0	6	5	500	-	141.41 €
CHC6-80/SS/B	M6	1.00	80	24	10.0	6	5	100	✓	60.78 €
CHC6-100/SS/B	M6	1.00	100	24	10.0	6	5	100	✓	80.33 €
CHC8-10/SS/B	M8	1.25	10	-	13.0	8	6	200	-	36.66 €
CHC8-16/SS/B	M8	1.25	16	-	13.0	8	6	200	✓	48.90 €
CHC8-20/SS/B	M8	1.25	20	-	13.0	8	6	200	✓	50.43 €
CHC8-25/SS/B	M8	1.25	25	-	13.0	8	6	200	✓	55.92 €
CHC8-30/SS/B	M8	1.25	30	-	13.0	8	6	200	✓	58.38 €
CHC8-35/SS/B	M8	1.25	35	-	13.0	8	6	200	✓	74.57 €
CHC8-40/SS/B	M8	1.25	40	28	13.0	8	6	200	✓	91.72 €
CHC8-50/SS/B	M8	1.25	50	28	13.0	8	6	200	✓	96.42 €
CHC8-60/SS/B	M8	1.25	60	28	13.0	8	6	200	✓	116.78 €
CHC8-70/SS/B	M8	1.25	70	28	13.0	8	6	200	-	76.34 €
CHC8-80/SS/B	M8	1.25	80	28	13.0	8	6	200	-	178.75 €
CHC10-16/SS/B	M10	1.50	16	-	16.0	10	8	100	-	35.40 €
CHC10-20/SS/B	M10	1.50	20	-	16.0	10	8	100	✓	34.49 €
CHC10-25/SS/B	M10	1.50	25	-	16.0	10	8	100	✓	44.37 €
CHC10-30/SS/B	M10	1.50	30	-	16.0	10	8	100	✓	52.87 €
CHC10-40/SS/B	M10	1.50	40	-	16.0	10	8	100	✓	61.89 €
CHC10-50/SS/B	M10	1.50	50	32	16.0	10	8	100	✓	36.96 €
CHC12-20/SS/B	M12	1.75	20	-	18.0	12	10	100	-	37.11 €
CHC12-30/SS/B	M12	1.75	30	-	18.0	12	10	100	-	40.61 €
CHC12-40/SS/B	M12	1.75	40	-	18.0	12	10	100	-	48.52 €
CHC12-50/SS/B	M12	1.75	50	36	18.0	12	10	100	-	55.11 €

*Dans la limite du disponible