 
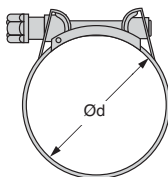


- Matières :
Tout inox AISI 304

Info.

- Vendu par multiple,
nous contacter

**REMISES**

Qté	1+	20+	40+	60+	100+	150+
Rem. Prix	-5%	-10%	-15%	-20%	Sur demande	

Références	Plage de serrage ØD	ØM	E	A	B	Valeur max.* Couple (daNcm)	Pression (Bar)	Prix Uni.
CSH20-34-37/SS	34-37	M7	10	22,0 \pm 0,3	22,0	16	46	4,70 €
CSH20-37-40/SS	37-40	M7	11	22,0 \pm 0,3	22,0	16	44	4,83 €
CSH20-40-43/SS	40-43	M7	12	22,0 \pm 0,3	22,0	16	44	4,89 €
CSH20-43-47/SS	43-47	M7	13	22,0 \pm 0,3	22,0	16	44	6,19 €
CSH20-47-51/SS	47-51	M7	14	22,0 \pm 0,3	22,0	16	44	6,28 €
CSH20-51-55/SS	51-55	M7	15	22,0 \pm 0,3	22,0	16	40	6,39 €
CSH20-55-59/SS	55-59	M7	16	22,0 \pm 0,3	22,0	16	40	6,49 €
CSH20-59-63/SS	59-63	M7	17	22,0 \pm 0,3	22,0	16	36	6,64 €
CSH20-63-68/SS	63-68	M7	18	22,0 \pm 0,3	22,0	16	36	6,94 €
CSH25-68-73/SS	68-73	M8	13	27,5 \pm 0,4	27,5	25	28	9,24 €
CSH25-73-79/SS	73-79	M8	14	27,5 \pm 0,4	27,5	25	28	9,66 €
CSH25-79-85/SS	79-85	M8	15	27,5 \pm 0,4	27,5	25	20	9,86 €
CSH25-85-91/SS	85-91	M8	16	27,5 \pm 0,4	27,5	25	20	9,95 €
CSH25-91-97/SS	91-97	M8	17	27,5 \pm 0,4	27,5	25	20	10,12 €
CSH25-97-104/SS	97-104	M8	18	27,5 \pm 0,4	27,5	25	20	10,37 €
CSH25-104-112/SS	104-112	M8	19	27,5 \pm 0,4	27,5	25	12	11,44 €
CSH25-112-121/SS	112-121	M8	20	27,5 \pm 0,4	27,5	25	12	11,83 €