


RAPPORT 2:1

Acier 60C40

- Module 0,8 à 6
- Angle de pression 20°
- Matière : acier 60C40
- Pour un couple, il faut deux pièces

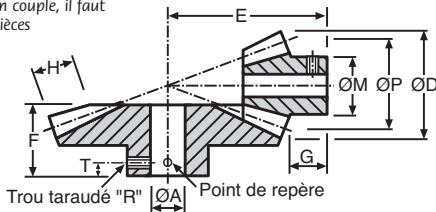

Les chiffres du couple sont doublés lors d'un traitement thermique

INDICATION DE COUPLE ET DE PUISSANCE	Pour 20 dents à 1000 t/min.									
	6 MOD	5 MOD	4 MOD	3 MOD	2,5 MOD	2 MOD	1,5 MOD	1,25 MOD	1 MOD	0,8 MOD
Couple (Nm)	51,00	32,00	16,40	7,70	4,30	2,20	0,94	0,71	0,57	0,14
Puissance (kW)	5,35	3,35	1,72	0,81	0,455	0,231	0,097	0,08	0,03	0,015

REMISES

Qté	1+	6+	20+	40+	60+	100+
Rem. Prix	-5%	-10%	-15%	-20%	Sur demande	

Références	Dents		ØP	E	ØD	ØA	ØM	F	G	H	Vis		Stock*	Prix Uni. 1 à 5
	Z	Mod									R	T		
DB0,8-15	15	0,8	12,00	20,0	13,93	6	10	11,90	7,50	4,02	M3	3,5	✓	23,94 €
DB0,8-30	30		24,00	14,0	24,64	8	20	10,08	5,50	4,02	M3	3,5	✓	27,71 €
DB1-15	15	1,0	15,00	24,0	17,42	8	14	13,87	8,76	5,03	M4	4,0	✓	27,14 €
DB1-30	30		30,00	18,0	30,58	10	25	13,11	7,00	5,03	M4	4,0	✓	33,35 €
DB1,5-15	15	1,5	22,50	35,0	26,12	10	21	19,84	12,13	7,55	M4	5,0	✓	29,58 €
DB1,5-30	30		45,00	27,0	45,87	10	30	19,66	11,00	7,55	M4	5,0	✓	37,88 €
DB2-15	15	2,0	30,00	45,0	34,83	12	28	24,76	14,86	10,06	M5	7,5	✓	32,74 €
DB2-30	30		60,00	35,0	61,16	12	40	25,21	14,00	10,06	M5	8,0	✓	45,40 €
DB2,5-15	15	2,5	37,50	54,0	43,54	15	32	29,51	16,51	13,53	M5	8,0	✓	44,76 €
DB2,5-30	30		75,00	41,5	76,45	15	50	29,31	13,31	13,53	M5	7,0	✓	56,53 €
DB3-15	15	3,0	45,00	65,0	52,25	18	36	36,26	18,00	17,00	M6	12,0	-	60,35 €
DB3-30	30		90,00	50,0	91,74	20	55	36,08	18,00	17,00	M6	12,0	-	111,24 €
DB4-15	15	4,0	60,00	85,0	69,67	20	48	46,11	22,01	22,00	M6	15,0	-	86,17 €
DB4-30	30		120,00	67,0	122,32	25	70	48,16	25,00	22,00	M8	15,0	-	130,59 €
DB5-15	15	5,0	75,00	100,0	87,09	20	60	51,81	21,00	28,00	M8	15,0	-	125,75 €
DB5-30	30		150,00	75,0	152,90	30	100	51,66	22,00	28,00	M10	15,0	-	181,93 €
DB6-15	15	6,0	90,00	115,0	104,51	25	75	57,52	21,00	34,00	M10	15,0	-	173,71 €
DB6-30	30		180,00	86,0	183,48	35	120	58,15	24,00	34,00	M10	15,0	-	210,80 €

*Dans la limite du disponible