


RAPPORT 2:1

Acier C43

- Module 1,5 à 5
- Angle de pression 20°
- Matière : acier C43
- Pour un couple, il faut deux pièces

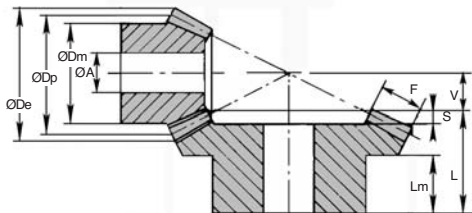

REMISES

Qté	1+	6+	20+	40+	60+	100+
Rem. Prix	-5%	-10%	-15%	-20%	Sur demande	

Références	Dent Z	mod	ØD _p	ØD _e	F	L	ØD _m	ØA	V	S	Lm	Prix Uni. 1 à 5
DB1.5-16/ECO	16	1,5	24	26,68	8	19,5	21	10	16,33	1,5	11,3	15,14 €
DB1.5-32/ECO	32		48	49,34	8	20,0	32	12	7,45	3,0	10,0	24,03 €
DB2-16/ECO	16	2	32	35,57	10	23,0	26	10	22,41	2,0	11,9	19,19 €
DB2-32/ECO	32		64	65,78	10	25,0	40	12	10,21	4,0	10,0	44,07 €
DB2.5-16/ECO	16	2,5	40	44,47	12	27,5	34	12	28,38	2,5	14,4	26,99 €
DB2.5-32/ECO	32		80	82,23	12	25,0	50	15	12,97	5,0	10,0	49,46 €
DB3-16/ECO	16	3	48	53,36	15	28,0	40	15	33,64	3,0	11,6	33,09 €
DB3-32/ECO	32		96	98,68	15	30,0	60	15	15,31	6,0	10,0	62,41 €
DB3.5-16/ECO	16	3,5	56	62,26	18	33,5	48	15	38,83	3,5	14,4	36,28 €
DB3.5-32/ECO	32		112	115,12	18	31,0	70	20	17,77	7,0	10,0	73,87 €
DB4-16/ECO	16	4	64	71,15	20	36,0	50	15	44,81	4,0	13,4	45,25 €
DB4-32/ECO	32		128	131,57	20	32,0	80	20	20,42	8,0	10,0	77,70 €
DB4.5-16/ECO	16	4,5	72	80,05	22	39,5	60	20	51,00	4,5	15,4	49,33 €
DB4.5-32/ECO	32		144	148,00	22	36,0	90	20	23,21	9,0	10,0	102,32 €
DB5-16/ECO	16	5	80	88,94	25	50,0	60	20	56,06	5,0	21,1	53,85 €
DB5-32/ECO	32		160	164,46	25	38,0	100	20	25,52	10,0	10,0	123,16 €