


- Module 1,5 à 5
- Angle de pression 20°
- Matière : acier C43
- Pour un couple, il faut deux pièces

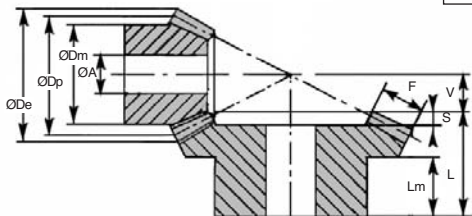

### REMISES

Qté	1+	6+	20+	40+	60+	100+
Rem. Prix	-5%	-10%	-15%	-20%	Sur demande	

Références	Dent Z	mod	OD <sub>p</sub>	OD <sub>e</sub>	F	L	OD <sub>m</sub>	OA	V	S	Lm	Prix Uni. 1 à 5
FB1.5-16/ECO	16	1,5	24	26,91	12	25,0	18	10	36,02	1,0	12,2	16,50 €
FB1.5-64/ECO	64	1,5	96	96,73	12	22,0	70	15	8,53	3,0	10,0	72,64 €
FB2-16/ECO	16	2	32	35,88	15	24,0	25	12	49,07	1,0	8,2	20,36 €
FB2-64/ECO	64	2	128	128,97	15	24,0	80	20	11,79	4,0	10,0	98,50 €
FB2.5-16/ECO	16	2,5	40	44,85	18	30,5	30	12	61,99	1,5	11,7	31,09 €
FB2.5-64/ECO	64	2,5	160	161,21	18	29,0	90	20	13,77	5,0	10,0	117,47 €
FB3-16/ECO	16	3	48	53,82	22	34,0	40	15	74,05	2,0	11,0	37,95 €
FB3-64/ECO	64	3	192	193,45	22	30,0	100	20	16,41	6,0	10,0	227,41 €
FB3.5-16/ECO	16	3,5	56	62,80	25	45,0	48	15	87,13	2,0	19,1	44,19 €
FB3.5-64/ECO	64	3,5	224	225,70	25	50,0	100	20	19,32	7,0	22,0	348,66 €
FB4-16/ECO	16	4	64	71,76	30	50,0	50	20	98,21	2,0	18,5	51,83 €
FB4-64/ECO	64	4	256	257,94	30	50,0	120	20	21,72	8,0	20,0	424,44 €
FB4.5-16/ECO	16	4,5	72	80,73	32	53,0	55	20	112,08	2,5	19,0	57,26 €
FB4.5-64/ECO	64	4,5	288	290,18	32	53,0	130	20	24,83	9,0	23,0	660,69 €
FB5-16/ECO	16	5	80	89,70	35	58,0	60	20	125,06	2,5	20,6	65,01 €
FB5-64/ECO	64	5	320	322,42	35	58,0	150	20	27,65	10,0	25,0	818,60 €