

Engrenage droit laiton




Module 1,0

Laiton CuZn40Pb3



- Classe de précision 9
- Angle de pression 20°

Indication de couple et de puissance		
Pour 50 dents à 1000 t/min.		
	20NCD2	Laiton
Nm	2,600	1,250
kW	0,254	0,134

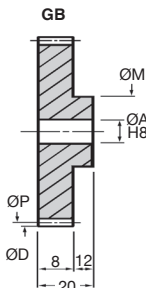

REMISES

Qté	1+	6+	20+	50+
Rem. Prix	-12%	-25%	Sur demande	

Références	Z Dents	ØP Primitif	ØD Extérieur	ØM Moyen	ØA Alésage	Stock*	Prix Uni. 1 à 5
GB1-12	12	12,00	14,00	14	6	✓	17,41 €
GB1-15	15	15,00	17,00	12	8	✓	18,11 €
GB1-18	18	18,00	20,00	15	8	-	19,36 €
GB1-20	20	20,00	22,00	15	8	✓	20,02 €
GB1-22	22	22,00	24,00	15	8	-	21,98 €
GB1-25	25	25,00	27,00	15	8	✓	23,90 €
GB1-28	28	28,00	30,00	15	8	-	25,86 €
GB1-30	30	30,00	32,00	20	8	✓	28,47 €
GB1-32	32	32,00	34,00	20	8	-	30,38 €
GB1-36	36	36,00	38,00	20	8	-	32,34 €
GB1-40	40	40,00	42,00	20	8	✓	33,96 €
GB1-44	44	44,00	46,00	20	8	-	36,85 €
GB1-48	48	48,00	50,00	20	8	-	45,28 €
GB1-50	50	50,00	52,00	30	10	✓	47,23 €
GB1-54	54	54,00	56,00	30	10	-	55,66 €
GB1-56	56	56,00	58,00	30	10	-	57,63 €
GB1-60	60	60,00	62,00	30	10	-	59,87 €
GB1-64	64	64,00	66,00	30	10	-	63,48 €
GB1-66	66	66,00	68,00	30	10	-	64,72 €
GB1-70	70	70,00	72,00	30	10	-	71,21 €
GB1-80	80	80,00	82,00	30	10	-	126,29 €
GB1-90	90	90,00	92,00	30	10	-	161,96 €
GB1-100	100	100,00	102,00	30	10	-	246,17 €

↓ Au choix : tout engrenage jusqu'à cette taille ↓			
GB1-590	590	590,00	592,00
Dimensions : contactez-nous		sur demande	

*Dans la limite du disponible - Dimensions en mm