 



Inox

GR

- Matière : Inox 303
- Longueur standard de 300mm à 1000mm cf. colonne L
- Tolérance diam.ext. h6
- Rectitude 0,01/300mm
- Etat de surface Ra 0,4

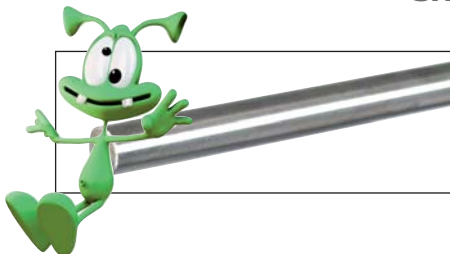

REMISES

Qté	1+	6+	20+	40+	60+	100+
Rem. Prix	-10%	-15%	-20%	-25%	Sur demande	

Références	ØD	L	Stock	Prix Uni. 1 à 5	Références	ØD	L	Stock	Prix Uni. 1 à 5
GR2.992-6	2,992	600	✓	13,62 €	GR9.993-1	9,993	1000	-	104,88 €
GR3.000-6	3,000	600	✓	13,62 €	GR10.000-4	10,000	400	✓	34,35 €
GR3.003-3	3,003	300	-	sur demande	GR10.000-9	10,000	900	-	88,05 €
GR3.003-6	3,003	600	-	sur demande	GR10.000-1	10,000	1000	-	104,88 €
GR3.992-6	3,992	600	✓	18,07 €	GR11.991-4	11,991	400	-	46,48 €
GR3.999-6	3,999	600	✓	16,13 €	GR11.991-9	11,991	900	-	sur demande
GR4.991-9	4,991	900	✓	27,34 €	GR11.993-1	11,993	1000	-	136,59 €
GR5.000-6	5,000	600	✓	17,07 €	GR12.000-4	12,000	400	✓	46,48 €
GR5.993-6	5,993	600	✓	22,55 €	GR12.000-9	12,000	900	-	120,77 €
GR5.992-9	5,992	900	-	33,69 €	GR12.000-1	12,000	1000	✓	139,05 €
GR6.000-6	6,000	600	✓	33,69 €	GR12.993-4	12,993	400	-	48,57 €
GR6.000-9	6,000	900	✓	33,69 €	GR12.993-9	12,993	900	-	sur demande
GR6.992-6	6,992	600	-	sur demande	GR13.993-9	13,993	900	-	142,07 €
GR6.992-9	6,992	900	-	sur demande	GR14.991-9	14,991	900	-	188,90 €
GR7.000-6	7,000	600	✓	25,66 €	GR15.974-9	15,974	900	-	sur demande
GR7.000-9	7,000	900	-	38,36 €	GR16.000-9	16,000	900	-	195,16 €
GR7.993-6	7,993	600	✓	31,63 €	GR19.992-9	19,992	900	✓	249,96 €
GR7.993-9	7,993	900	-	47,37 €	GR24.993-9	24,993	900	-	sur demande
GR8.000-6	8,000	600	✓	30,01 €	GR25.000-9	25,000	900	-	348,53 €
GR8.992-9	8,992	900	-	84,53 €	GR29.992-9	29,992	900	-	474,19 €
GR9.992-9	9,992	900	✓	88,67 €					

*Dans la limite du disponible