


- Colonne femelle/femelle
- Matière : inox 303
- Conditionnées par lot

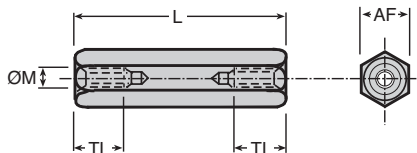

REMISES

Nb. lot	1+	5+	20+	50+
Rem.	Prix -20%	-30%	Sur demande	

Références	Filetage ØM	L	TL	AF	Qté par lot	Stock*	Prix Uni. par lot
HS3-5/B	M3	5	5	5,5	20	✓	13,02 €
HS3-8/B	M3	8	8	5,5	20	-	13,76 €
HS3-10/B	M3	10	10	5,5	20	✓	14,04 €
HS3-12/B	M3	12	12	5,5	20	✓	15,53 €
HS3-15/B	M3	15	15	5,5	20	✓	17,11 €
HS3-18/B	M3	18	18	5,5	20	✓	19,39 €
HS3-20/B	M3	20	20	5,5	20	✓	21,28 €
HS3-25/B	M3	25	10	5,5	20	-	22,40 €
HS3-35/B	M3	35	10	5,5	20	✓	24,88 €
HS3-40/B	M3	40	10	5,5	20	-	25,51 €
HS3-45/B	M3	45	10	5,5	20	-	26,23 €
HS4-5/B	M4	5	5	7,0	20	-	15,41 €
HS4-8/B	M4	8	8	7,0	20	-	16,79 €
HS4-10/B	M4	10	10	7,0	20	✓	18,36 €
HS4-12/B	M4	12	12	7,0	20	✓	19,68 €
HS4-15/B	M4	15	15	7,0	20	-	22,04 €
HS4-18/B	M4	18	18	7,0	20	-	23,98 €
HS4-20/B	M4	20	20	7,0	20	✓	24,39 €
HS4-25/B	M4	25	10	7,0	20	✓	24,76 €

*Dans la limite du disponible