




- Classe de précision 9
- Angle de pression 20°

### Indication de couple et de puissance

Pour 50 dents à 1000 t/min.

	INOX 303	laiton	fibre	
Nm				
kW				

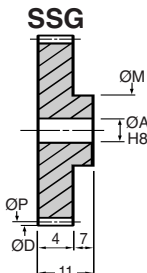

### REMISES

Qté	1+	6+	20+
Rem. Prix	-12%	Sur demande	

Références	Z Dents	ØP Primitif	ØD Extérieur	ØM Moyeu	ØA Alésage	Stock*	Prix Uni. 1 à 5
SSG0.5-12-303	12	6,0	7,0	7,0	3	-	16,30 €
SSG0.5-15-303	15	7,5	8,5	8,5	3	-	16,84 €
SSG0.5-16-303	16	8,0	9,0	8,5	4	-	17,15 €
SSG0.5-18-303	18	9,0	10,0	8,5	4	-	17,36 €
SSG0.5-20-303	20	10,0	11,0	8,5	4	-	17,88 €
SSG0.5-22-303	22	11,0	12,0	8,5	4	-	18,30 €
SSG0.5-24-303	24	12,0	13,0	10,0	5	-	18,79 €
SSG0.5-25-303	25	12,5	13,5	10,0	5	-	18,93 €
SSG0.5-26-303	26	13,0	14,0	10,0	5	-	19,21 €
SSG0.5-28-303	28	14,0	15,0	10,0	5	-	19,74 €
SSG0.5-30-303	30	15,0	16,0	10,0	5	-	19,84 €
SSG0.5-32-303	32	16,0	17,0	10,0	5	-	20,31 €
SSG0.5-36-303	36	18,0	19,0	10,0	5	-	21,19 €
SSG0.5-40-303	40	20,0	21,0	10,0	5	-	22,09 €
SSG0.5-44-303	44	22,0	23,0	10,0	5	-	22,97 €
SSG0.5-48-303	48	24,0	25,0	10,0	5	-	24,06 €
SSG0.5-50-303	50	25,0	26,0	12,0	6	-	24,38 €
SSG0.5-54-303	54	27,0	28,0	12,0	6	-	25,00 €
SSG0.5-56-303	56	28,0	29,0	12,0	6	-	25,37 €
SSG0.5-60-303	60	30,0	31,0	12,0	6	-	26,03 €
SSG0.5-64-303	64	32,0	33,0	12,0	6	-	28,55 €
SSG0.5-70-303	70	35,0	36,0	12,0	6	-	29,27 €
SSG0.5-80-303	80	40,0	41,0	12,0	6	-	30,42 €

**Au choix : tout engrenage jusqu'à cette taille**

SSG0.5-278-303	278	139,0	140,0	Dimensions : contactez-nous		sur demande
----------------	-----	-------	-------	-----------------------------	--	-------------

\*Dans la limite du disponible