



# Engrenage droit **inox**

Inox 316L


MODULE

**0,5**



- Classe de précision 9
- Angle de pression 20°

Indication de couple et de puissance				
Pour 50 dents à 1000 t/min.				
	INOX 316L	laiton	fibre	
Nm				
kW				

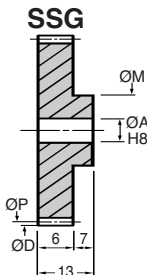

### REMISES

Qté	1+	6+	20+
Rem.	Prix	-12%	Sur demande

Références	Z Dents	ØP Primitif	ØD Extérieur	ØM Moyeu	ØA Alésage	Prix Uni. 1 à 5
SSG0.5-12-316L	12	6,0	7,0	7,0	3	30,55 €
SSG0.5-15-316L	15	7,5	8,5	8,5	3	31,58 €
SSG0.5-16-316L	16	8,0	9,0	8,5	4	32,16 €
SSG0.5-18-316L	18	9,0	10,0	8,5	4	32,56 €
SSG0.5-20-316L	20	10,0	11,0	8,5	4	33,55 €
SSG0.5-22-316L	22	11,0	12,0	8,5	4	34,31 €
SSG0.5-24-316L	24	12,0	13,0	10,0	5	35,25 €
SSG0.5-25-316L	25	12,5	13,5	10,0	5	35,51 €
SSG0.5-26-316L	26	13,0	14,0	10,0	5	36,02 €
SSG0.5-28-316L	28	14,0	15,0	10,0	5	37,00 €
SSG0.5-30-316L	30	15,0	16,0	10,0	5	37,20 €
SSG0.5-32-316L	32	16,0	17,0	10,0	5	38,08 €
SSG0.5-36-316L	36	18,0	19,0	10,0	5	39,73 €
SSG0.5-40-316L	40	20,0	21,0	10,0	5	41,43 €
SSG0.5-44-316L	44	22,0	23,0	10,0	5	43,07 €
SSG0.5-48-316L	48	24,0	25,0	10,0	5	45,14 €
SSG0.5-50-316L	50	25,0	26,0	12,0	6	45,72 €
SSG0.5-54-316L	54	27,0	28,0	12,0	6	46,90 €
SSG0.5-56-316L	56	28,0	29,0	12,0	6	47,56 €
SSG0.5-60-316L	60	30,0	31,0	12,0	6	48,81 €
SSG0.5-64-316L	64	32,0	33,0	12,0	6	53,54 €
SSG0.5-70-316L	70	35,0	36,0	12,0	6	54,88 €
SSG0.5-80-316L	80	40,0	41,0	12,0	6	57,06 €



**Au choix : tout engrenage jusqu'à cette taille**



SSG0.5-278-316L	278	139,0	140,0	Dimensions : contactez-nous		sur demande
-----------------	-----	-------	-------	-----------------------------	--	-------------