




- Classe de précision 9
- Angle de pression 20°

Indication de couple et de puissance				
Pour 50 dents à 1000 t/min.				
	INOX 303	laiton	fibre	
Nm				
kW				

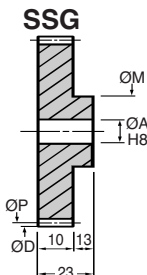

REMISES

Qté	1+	6+	20+
Rem. Prix	-12%		Sur demande

Références	Z Dents	ØP Primitif	ØD Extérieur	ØM Moyeu	ØA Alésage	Stock*	Prix Uni. 1 à 5
SSG1.5-12-303	12	18,0	21,0	14	8	-	20,08 €
SSG1.5-15-303	15	22,5	25,5	18	8	-	22,17 €
SSG1.5-16-303	16	24,0	27,0	20	10	-	23,11 €
SSG1.5-18-303	18	27,0	30,0	20	10	-	26,00 €
SSG1.5-20-303	20	30,0	33,0	20	10	-	27,61 €
SSG1.5-22-303	22	33,0	36,0	20	10	-	30,53 €
SSG1.5-24-303	24	36,0	39,0	25	10	-	31,94 €
SSG1.5-30-303	30	45,0	48,0	25	10	-	40,48 €
SSG1.5-32-303	32	48,0	51,0	25	10	-	43,46 €
SSG1.5-36-303	36	54,0	57,0	30	15	-	49,97 €
SSG1.5-40-303	40	60,0	63,0	40	15	-	53,04 €
SSG1.5-44-303	44	66,0	69,0	40	15	-	53,18 €
SSG1.5-46-303	46	69,0	72,0	40	15	-	55,47 €
SSG1.5-48-303	48	72,0	75,0	40	15	-	58,02 €
SSG1.5-50-303	50	75,0	78,0	40	15	-	80,35 €
SSG1.5-54-303	54	81,0	84,0	40	15	-	80,35 €
SSG1.5-56-303	56	84,0	87,0	40	15	-	80,35 €
SSG1.5-60-303	60	90,0	93,0	40	15	-	110,43 €
SSG1.5-64-303	64	96,0	99,0	40	15	-	110,43 €
SSG1.5-66-303	66	99,0	102,0	40	15	-	126,65 €
SSG1.5-70-303	70	105,0	108,0	40	15	-	126,65 €



Au choix : tout engrenage jusqu'à cette taille



SSG1.5-298-303 298 447,0 450,0 Dimensions : contactez-nous sur demande

*Dans la limite du disponible