



Engrenage droit **inox**

Inox 316L


MODULE

1,5



- Classe de précision 9
- Angle de pression 20°

Indication de couple et de puissance Pour 50 dents à 1000 t/min.				
	INOX 316L	laiton	fibre	
Nm				
kW				

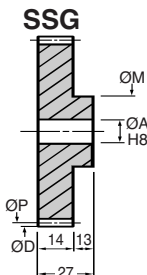

REMISES

Qté	1+	6+	20+
Rem. Prix		-12%	Sur demande

Références	Z Dents	ØP Primitif	ØD Extérieur	ØM Moyeu	ØA Alésage	Prix Uni. 1 à 5
SSG1.5-12-316L	12	18,0	21,0	14	8	37,66 €
SSG1.5-15-316L	15	22,5	25,5	18	8	41,59 €
SSG1.5-16-316L	16	24,0	27,0	20	10	43,34 €
SSG1.5-18-316L	18	27,0	30,0	20	10	48,75 €
SSG1.5-20-316L	20	30,0	33,0	20	10	51,79 €
SSG1.5-22-316L	22	33,0	36,0	20	10	57,25 €
SSG1.5-24-316L	24	36,0	39,0	25	10	59,88 €
SSG1.5-30-316L	30	45,0	48,0	25	10	75,91 €
SSG1.5-32-316L	32	48,0	51,0	25	10	81,49 €
SSG1.5-36-316L	36	54,0	57,0	30	15	93,70 €
SSG1.5-40-316L	40	60,0	63,0	40	15	99,47 €
SSG1.5-44-316L	44	66,0	69,0	40	15	99,73 €
SSG1.5-46-316L	46	69,0	72,0	40	15	104,01 €
SSG1.5-48-316L	48	72,0	75,0	40	15	108,79 €
SSG1.5-50-316L	50	75,0	78,0	40	15	150,65 €
SSG1.5-54-316L	54	81,0	84,0	40	15	150,65 €
SSG1.5-56-316L	56	84,0	87,0	40	15	150,65 €
SSG1.5-60-316L	60	90,0	93,0	40	15	207,04 €
SSG1.5-64-316L	64	96,0	99,0	40	15	207,04 €
SSG1.5-66-316L	66	99,0	102,0	40	15	237,50 €
SSG1.5-70-316L	70	105,0	108,0	40	15	237,50 €



Au choix : tout engrenage jusqu'à cette taille



SSG1.5-298-316L	298	447,0	450,0	Dimensions : contactez-nous		sur demande
-----------------	-----	-------	-------	-----------------------------	--	-------------