


- Module 1,5 à 5
- Angle de pression 20°
- Matière :
Acier C43
- Pour un couple, il faut deux pièces

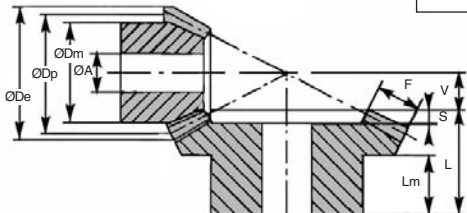

REMISES

Qté	1+	6+	20+	40+	60+	100+
Rem.	Prix	-5%	-10%	-15%	-20%	Sur demande

Références	Dent Z	mod	OD _p	OD _e	F	L	OD _m	OA	V	S	Lm	Prix Uni. 1 à 5
TB1.5-16/ECO	16	1,5	24	26,82	12	24,0	20	10	24,42	1,0	11,7	16,84 €
TB1.5-48/ECO	48		72	72,95	12	20,0	50	12	7,27	3,0	10,0	51,83 €
TB2-16/ECO	16	2	32	35,80	15	28,5	26	12	33,26	1,5	12,4	19,94 €
TB2-48/ECO	48		96	97,26	15	23,0	60	15	9,90	4,0	10,0	65,01 €
TB2.5-16/ECO	16	2,5	40	44,74	18	32,0	32	12	42,41	1,5	13,0	30,02 €
TB2.5-48/ECO	48		120	121,58	18	26,0	70	20	12,60	5,0	10,0	75,82 €
TB3-16/ECO	16	3	48	53,69	18	32,0	40	15	54,25	2,0	12,1	33,80 €
TB3-48/ECO	48		144	145,90	18	29,0	80	20	16,20	6,0	10,0	91,60 €
TB3.5-16/ECO	16	3,5	56	62,64	22	38,0	48	15	62,29	2,5	15,0	42,97 €
TB3.5-48/ECO	48		168	170,21	22	31,0	90	20	18,48	7,0	10,0	121,26 €
TB4-16/ECO	16	4	64	71,59	25	41,5	55	20	71,23	3,0	15,2	48,40 €
TB4-48/ECO	48		192	194,53	25	33,0	100	20	21,20	8,0	10,0	202,12 €
TB4.5-16/ECO	16	4,5	72	80,53	28	53,0	60	20	80,27	3,0	23,4	55,47 €
TB4.5-48/ECO	48		216	218,84	28	49,0	100	20	23,93	9,0	18,0	366,34 €
TB5-16/ECO	16	5	80	89,48	35	60,0	60	20	85,61	3,0	22,5	60,74 €
TB5-48/ECO	48		240	243,16	35	50,0	150	20	25,45	10,0	20,0	435,80 €