


- **Bronze bearing**
- Conforms to ISO 2795
- Tolerance G7/s7 G8/s8
- Materials: sintered bronze saturated with mineral oil
- Static load 50 N/mm<sup>2</sup>
- Dynamic load 15 N/mm<sup>2</sup>
- Working temp. -9°C to +70°C
- Fits bore-sizes H7

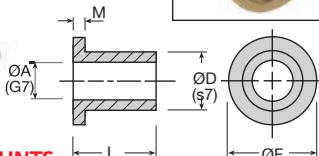

European standard versions also available - see METC range

### DISCOUNTS

Qty	1+	10+	25+	50+	100+	200+	500+
Disc.		-20%	-30%	-40%	-50%	-60%	On request

Part number	ØA	L	ØD	ØF	M	Stock	Price each	
							1 to 9	10 to 9
QFM3	Ø2	3	5	8	1,5	-	4,78 €	
QFM5	Ø3	4	6	9	1,5	✓	4,78 €	
QFM6-4	Ø4	4	8	12	2,0	✓	4,94 €	
QFM6-6	Ø4	6	8	12	2,0	✓	4,94 €	
QFM7-4	Ø5	4	9	13	2,0	✓	5,74 €	
QFM7-5	Ø5	5	9	13	2,0	✓	5,74 €	
QFM7-8	Ø5	8	9	13	2,0	✓	5,74 €	
QFM8-4	Ø6	4	10	14	2,0	✓	5,74 €	
QFM8-6	Ø6	6	10	14	2,0	✓	5,74 €	
QFM8-10	Ø6	10	10	14	2,0	✓	5,74 €	
QFM9-8	Ø7	8	11	15	2,0	✓	5,74 €	
QFM10-6	Ø8	6	12	16	2,0	✓	6,16 €	
QFM10-8	Ø8	8	12	16	2,0	✓	6,16 €	
QFM10-12	Ø8	12	12	16	2,0	✓	6,16 €	
QFM12-8	Ø10	8	16	22	3,0	✓	6,99 €	
QFM12-10	Ø10	10	16	22	3,0	✓	6,99 €	
QFM12-16	Ø10	16	16	22	3,0	✓	8,69 €	
QFM13-8	Ø12	8	18	24	3,0	✓	8,02 €	
QFM13-12	Ø12	12	18	24	3,0	✓	8,02 €	
QFM13-20	Ø12	20	18	24	3,0	✓	10,48 €	
QFM14-10	Ø14	10	20	26	3,0	-	8,83 €	
QFM14-14	Ø14	14	20	26	3,0	✓	8,83 €	
QFM14-20	Ø14	20	20	26	3,0	✓	10,80 €	
QFM15-10	Ø15	10	21	27	3,0	-	10,24 €	
QFM15-15	Ø15	15	21	27	3,0	-	10,24 €	
QFM15-20	Ø15	20	21	27	3,0	-	13,07 €	
QFM15-25	Ø15	25	21	27	3,0	-	13,07 €	

Part number	ØA	L	ØD	ØF	M	Stock	Price each	
							1 to 9	10 to 9
QFM16-12	Ø16	12	22	28	3,0	✓	10,80 €	
QFM16-16	Ø16	16	22	28	3,0	✓	10,80 €	
QFM16-25	Ø16	25	22	28	3,0	✓	14,59 €	
QFM17-12	Ø18	12	24	30	3,0	-	11,49 €	
QFM17-18	Ø18	18	24	30	3,0	-	14,90 €	
QFM17-30	Ø18	30	24	30	3,0	-	20,19 €	
QFM18-15	Ø20	15	26	32	3,0	✓	13,50 €	
QFM18-20	Ø20	20	26	32	3,0	✓	16,14 €	
QFM18-25	Ø20	25	26	32	3,0	✓	20,10 €	
QFM18-30	Ø20	30	26	32	3,0	-	23,44 €	
QFM20-20	Ø25	20	30	39	3,5	✓	17,03 €	
QFM20-25	Ø25	25	30	39	3,5	-	31,19 €	
QFM20-32	Ø25	32	30	39	3,5	-	23,91 €	
QFM24-20	Ø30	20	38	46	4,0	-	23,27 €	
QFM24-25	Ø30	25	38	46	4,0	-	26,37 €	
QFM24-30	Ø30	30	38	46	4,0	-	31,73 €	
QFM27-25	Ø35	25	45	55	5,0	-	34,90 €	
QFM27-35	Ø35	35	45	55	5,0	-	44,96 €	
QFM27-40	Ø35	40	45	55	5,0	-	50,55 €	
QFM30-25	Ø40	25	50	60	5,0	-	59,46 €	
QFM30-30	Ø40	30	50	60	5,0	-	62,49 €	
QFM30-40	Ø40	40	50	60	5,0	-	68,51 €	
QFM30-50	Ø40	50	50	60	5,0	-	73,72 €	
QFM32-32	Ø50	32	60	70	5,0	-	66,60 €	
QFM32-40	Ø50	40	60	70	5,0	-	71,55 €	
QFM32-50	Ø50	50	60	70	5,0	-	82,50 €	

\*Depending on availability - Dimensions in mm

## Our other products



CHALss

Piano hinge, Stainless steel



RPCplss

Wheel pivoting with plate, Stainless steel - Polyamide



VRSF

Lifting ring, Male swivelling



JCDss

Universal joint - stainless steel, Plain bearings - double




DBC

Panamech, Multi-Beam, Aluminium - with clamping jaw



CLG3

 Spur gear, Moulded plastic (nylon)



PO

Housing handle - Multi-sector, Smooth hole



RURp

Pivoting wheel with double brake, Polyurethane - Aluminium rim (Free



RAGFLOW

Handling roller, Roller track



PSG25DL

Spur gear - precision range, Delrin



BAC110

Storage bin, Storage bin



PRF\_PL\_4590

Connecting/joining, Joint plate - 45x90 mm

## Complementary products



QM

Bushing, Self-lubricating sintered bronze OILITE



METC

Bushing, Self-lubricating sintered bronze