


MADE TO MEASURE

LINEAR SHAFTS

Need a different END?
Made to measure
versions available!
Contact us...

A wide choice of
different materials

Choice of alternative
shaft lengths and
diameters

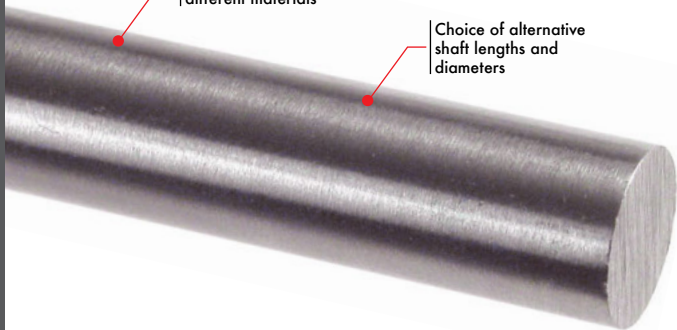

HPC can offer you a wide range of modifications
to our standard linear shafts:

- shorter or longer lengths
- bores
- diameters
- materials
- specific finishing treatments
- machining

Contact our technical support team
for more information!


MADE TO MEASURE

LINEAR SHAFTS PLEASE FILL IN THE DETAILS

Min
quantity


Please send us your drawings!
Email address: cial2@hpceurope.com
Tel: +33(0)4 37 496 496
Fax: +33(0)4 37 490 055

Type 1

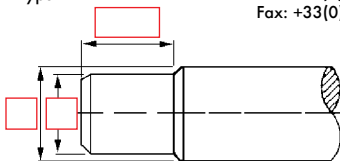


- Alternative diameters
- Machined or hardened versions available

Type 2: Threaded end

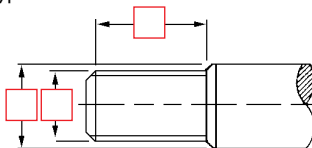


- Annealed end
- Non-hardened thread
- End undercut with or without groove for circlip

Type 3: End with transversal hole

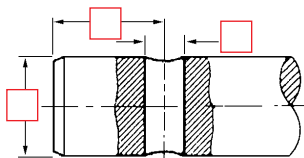

- Shaft annealed around the bore or milled on both sides

 Type 4: End with groove for circlip



- Shaft tempered/softened or annealed as required