

# Linear ball bearings + shaft

## Possible combinations

### Closed linear ball bearing:



Ref. KH  
(tome 3 p.242)



Ref. KBSuu  
(tome 3 p.247)



Ref. KKB  
(tome 3 p.250)



Ref. LBE  
(tome 3 p.244)



Ref. TKuu  
(tome 3 p.248)



Ref. KKP  
(tome 3 p.251)




Ref. KBww,  
KBSww  
(tome 3 p.245)



Ref. RJZM,  
RJUM  
(tome 3 p.249)



Ref. KBuu  
(tome 3 p.246)

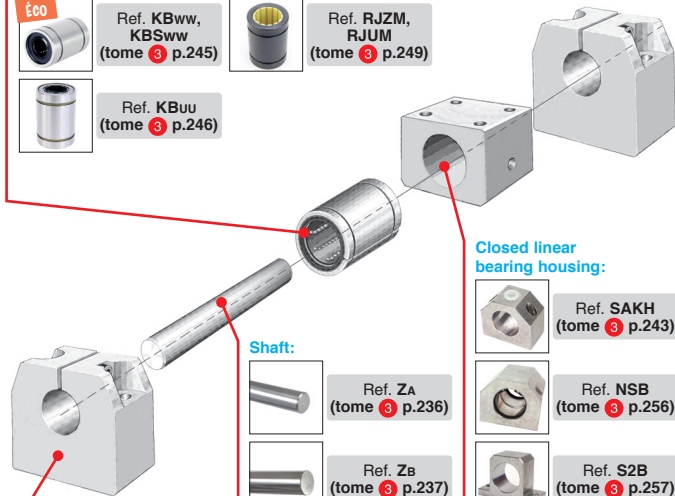

### Closed linear bearing housing:



Ref. SAKH  
(tome 3 p.243)



Ref. NSB  
(tome 3 p.256)



Ref. S2B  
(tome 3 p.257)



Ref. RJUM05,  
RJUM06  
(tome 3 p.260)

### Shaft:



Ref. ZA  
(tome 3 p.236)



Ref. Zb  
(tome 3 p.237)



Ref. AWMP  
(tome 3 p.235)

### Shaft end supports:



Ref. FGWA  
(tome 3 p.241)



Ref. SFWR  
(tome 3 p.240)

# Linear ball bearings + shaft

## Possible combinations

