

Spur gear coaxial gearbox



J,XJ,NT,NH,
JHD,XJHD

Technical information

- **Speed ratio: from 1:1 to 625:1**
- **Materials :**
 - Housing - anodised aluminium and black Delrin
 - Gears - stainless steel, steel
 - Case hardened steel depending on model
- **Max. speed: 3,000 to 4,000 rpm on input depending on model**
- **Lubrication: greased for life**
- **Guarantee: 13 months**
- **Cooling may be needed dependent on application**



J, XJ range

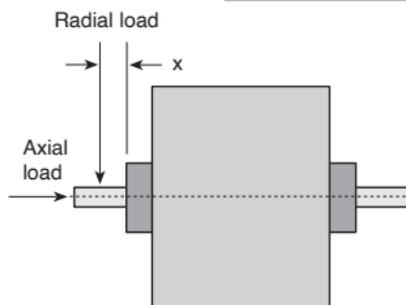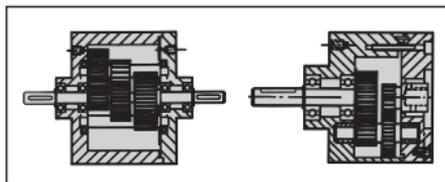

ADMISSIBLE LOADS

Part number	Distance 'X' (mm)	Output	
		Radial load (N)	Axial load (N)
J & XJ51-52-53	6	10	10
J & XJ64-65-66	6	20	20
NT & NH61-62-63	10	120	100
NT & NH91-92	15	200	150
NH & NH121-122	20	250	200

Data given based on input speed of 1,000 rpm.
Values given as an indication only.