




Charges admissibles

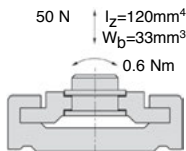


50 N
 $I_y=1700\text{mm}^4$
 $W_b=200\text{mm}^3$
NK02-17

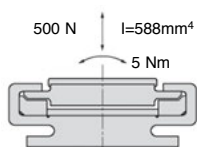

$I=6524\text{mm}^4$
NK01-27
NK02-27

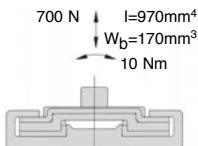

700 N
 $I=26400\text{mm}^4$
 $W_b=660\text{mm}^3$
NK02-40

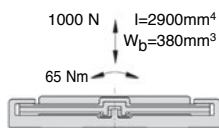

1000 N
NK02-80

Charges dynamiques admissibles maxi pour Drylin® N

