
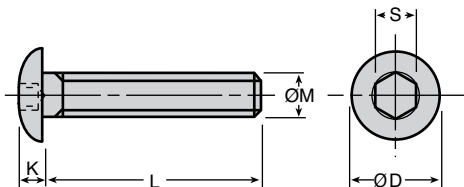


- Selon ISO 7380
- Matière :
Inox 302/304-A2
- 6 pans creux
- Conditionnée par lot

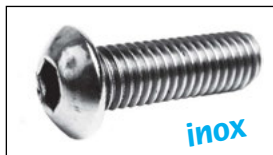

REMISES

Nb. lots	1+	6+	10+
Rem.	Prix	-5%	Sur demande

Références	Filetage		Longueur			Quantité par lot	Stock*	Prix Uni. par lot
	ØM	Pas	L	ØD	K			
BHC4-8/SS/B	M4	0,70	8	7,6	2,20	2,5	500	✓ 28,83 €
BHC4-10/SS/B	M4	0,70	10	7,6	2,20	2,5	500	✓ 34,57 €
BHC4-12/SS/B	M4	0,70	12	7,6	2,20	2,5	500	✓ 23,02 €
BHC4-16/SS/B	M4	0,70	16	7,6	2,20	2,5	500	- 32,04 €
BHC5-10/SS/B	M5	0,80	10	9,5	2,75	3,0	500	✓ 38,39 €
BHC5-12/SS/B	M5	0,80	12	9,5	2,75	3,0	500	✓ 27,89 €
BHC5-16/SS/B	M5	0,80	16	9,5	2,75	3,0	500	- 31,07 €
BHC5-20/SS/B	M5	0,80	20	9,5	2,75	3,0	500	✓ 62,52 €
BHC6-12/SS/B	M6	1,00	12	10,5	3,30	4,0	500	✓ 61,45 €
BHC6-16/SS/B	M6	1,00	16	10,5	3,30	4,0	500	- 69,13 €
BHC6-20/SS/B	M6	1,00	20	10,5	3,30	4,0	500	✓ 79,89 €
BHC6-25/SS/B	M6	1,00	25	10,5	3,30	4,0	500	- 56,59 €
BHC8-16/SS/B	M8	1,25	16	14,0	4,40	5,0	200	✓ 37,04 €
BHC8-20/SS/B	M8	1,25	20	14,0	4,40	5,0	200	✓ 58,64 €
BHC8-25/SS/B	M8	1,25	25	14,0	4,40	5,0	200	- 69,85 €
BHC8-30/SS/B	M8	1,25	30	14,0	4,40	5,0	200	- 65,13 €

*Dans la limite du disponible - Dimensions en mm