
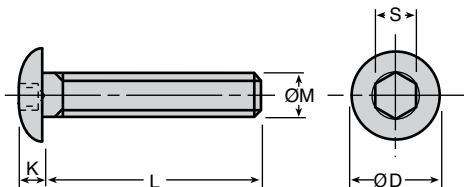


## BHC

## Inox A2

- Selon ISO 7380
- Matière :  
Inox 302/304-A2
- 6 pans creux
- Conditionnée par lot

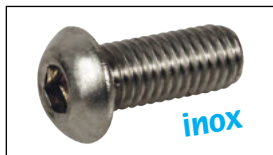

NOUVELLES  
REMISES

### REMISES

Nb. lots	1+	2+	4+
Rem.	Prix	-20%	Sur demande

Références	Filetage		Longueur			Quantité par lot	Stock*	Prix Uni. par lot
	ØM	Pas	L	ØD	K			
BHC4-8/SS/B	M4	0,70	8	7,6	2,20	2,5	500	✓ 12,14 €
BHC4-10/SS/B	M4	0,70	10	7,6	2,20	2,5	500	✓ 12,49 €
BHC4-12/SS/B	M4	0,70	12	7,6	2,20	2,5	500	✓ 19,42 €
BHC4-16/SS/B	M4	0,70	16	7,6	2,20	2,5	500	- 20,46 €
BHC5-10/SS/B	M5	0,80	10	9,5	2,75	3,0	500	✓ 21,85 €
BHC5-12/SS/B	M5	0,80	12	9,5	2,75	3,0	500	✓ 30,36 €
BHC5-16/SS/B	M5	0,80	16	9,5	2,75	3,0	500	- 33,14 €
BHC5-20/SS/B	M5	0,80	20	9,5	2,75	3,0	500	✓ 36,25 €
BHC6-12/SS/B	M6	1,00	12	10,5	3,30	4,0	500	✓ 33,66 €
BHC6-16/SS/B	M6	1,00	16	10,5	3,30	4,0	500	- 40,26 €
BHC6-20/SS/B	M6	1,00	20	10,5	3,30	4,0	500	✓ 46,67 €
BHC6-25/SS/B	M6	1,00	25	10,5	3,30	4,0	500	- 44,07 €
BHC8-16/SS/B	M8	1,25	16	14,0	4,40	5,0	200	✓ 30,67 €
BHC8-20/SS/B	M8	1,25	20	14,0	4,40	5,0	200	✓ 34,70 €
BHC8-25/SS/B	M8	1,25	25	14,0	4,40	5,0	200	- 38,37 €
BHC8-30/SS/B	M8	1,25	30	14,0	4,40	5,0	200	- 35,18 €

\*Dans la limite du disponible - Dimensions en mm