

- Selon ISO 4762 et DIN 912

- Matière :


Inox 302/304 - A2

- 6 Pans creux

- Conditionnées par lot

Utilisation

- Environnement difficile

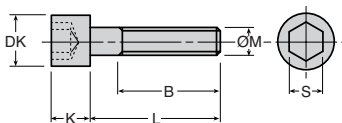

REMISES

Nb. Lots	1+	6+	10+
Rem.	Prix	-5%	Sur demande

Références	Filetage ØM	Pas	Longueur totale L	B	DK	K	S	Qté par lot	Stock*	Prix Uni. par lot
CHC1.6-5/SS/B	M1,6	0,35	5	-	3,0	1,6	1,5	200	-	11,07 €
CHC1.6-8/SS/B	M1,6	0,35	8	-	3,0	1,6	1,5	200	✓	30,94 €
CHC1.6-10/SS/B	M1,6	0,35	10	-	3,0	1,6	1,5	200	✓	24,05 €
CHC2-4/SS/B	M2	0,40	4	-	3,8	2,0	1,5	500	-	39,25 €
CHC2-5/SS/B	M2	0,40	5	-	3,8	2,0	1,5	500	✓	36,59 €
CHC2-6/SS/B	M2	0,40	6	-	3,8	2,0	1,5	500	✓	28,74 €
CHC2-8/SS/B	M2	0,40	8	-	3,8	2,0	1,5	500	✓	48,09 €
CHC2-10/SS/B	M2	0,40	10	-	3,8	2,0	1,5	500	✓	32,93 €
CHC2-12/SS/B	M2	0,40	12	-	3,8	2,0	1,5	500	✓	34,50 €
CHC2-20/SS/B	M2	0,40	20	-	3,8	2,0	1,5	500	✓	73,70 €
CHC2.5-4/SS/B	M2,5	0,45	4	-	4,5	2,5	2,0	500	-	27,96 €
CHC2.5-5/SS/B	M2,5	0,45	5	-	4,5	2,5	2,0	500	-	31,88 €
CHC2.5-6/SS/B	M2,5	0,45	6	-	4,5	2,5	2,0	500	-	23,78 €
CHC2.5-8/SS/B	M2,5	0,45	8	-	4,5	2,5	2,0	500	✓	25,61 €
CHC2.5-10/SS/B	M2,5	0,45	10	-	4,5	2,5	2,0	500	-	23,52 €
CHC2.5-16/SS/B	M2,5	0,45	16	-	4,5	2,5	2,0	500	✓	31,36 €
CHC2.5-20/SS/B	M2,5	0,45	20	-	4,5	2,5	2,0	500	✓	45,47 €
CHC3-6/SS/B	M3	0,50	6	-	5,5	3,0	2,5	1000	✓	49,65 €
CHC3-8/SS/B	M3	0,50	8	-	5,5	3,0	2,5	1000	✓	51,74 €
CHC3-10/SS/B	M3	0,50	10	-	5,5	3,0	2,5	1000	✓	54,16 €
CHC3-12/SS/B	M3	0,50	12	-	5,5	3,0	2,5	1000	✓	37,11 €
CHC3-16/SS/B	M3	0,50	16	-	5,5	3,0	2,5	1000	✓	61,14 €
CHC3-20/SS/B	M3	0,50	20	-	5,5	3,0	2,5	1000	✓	66,68 €
CHC3-25/SS/B	M3	0,50	25	18	5,5	3,0	2,5	1000	✓	55,93 €
CHC3-30/SS/B	M3	0,50	30	18	5,5	3,0	2,5	1000	✓	96,94 €
CHC3-35/SS/B	M3	0,50	35	18	5,5	3,0	2,5	500	-	53,57 €
CHC4-6/SS/B	M4	0,70	6	-	7,0	4,0	3,0	500	✓	33,00 €
CHC4-8/SS/B	M4	0,70	8	-	7,0	4,0	3,0	500	✓	24,10 €
CHC4-10/SS/B	M4	0,70	10	-	7,0	4,0	3,0	500	✓	31,91 €

*Dans la limite du disponible - Dimensions en mm

REMISES

Nb. Lots Rem.	1+	6+	10+
	Prix	-5%	Sur demande

Références	Filetage		Longueur				S	Qté par lot	Stock*	Prix Uni. par lot
	ØM	Pas	totale L	B	DK	K				
CHC4-12/SS/B	M4	0,70	12	-	7,0	4	3	500	✓	36,45 €
CHC4-16/SS/B	M4	0,70	16	-	7,0	4	3	500	✓	24,92 €
CHC4-20/SS/B	M4	0,70	20	-	7,0	4	3	500	✓	33,59 €
CHC4-25/SS/B	M4	0,70	25	-	7,0	4	3	500	✓	38,53 €
CHC4-30/SS/B	M4	0,70	30	20	7,0	4	3	500	✓	51,69 €
CHC4-35/SS/B	M4	0,70	35	20	7,0	4	3	500	✓	44,89 €
CHC4-40/SS/B	M4	0,70	40	20	7,0	4	3	500	✓	71,56 €
CHC4-50/SS/B	M4	0,70	50	20	7,0	4	3	200	✓	35,03 €
CHC5-8/SS/B	M5	0,80	8	-	8,5	5	4	500	✓	46,01 €
CHC5-10/SS/B	M5	0,80	10	-	8,5	5	4	500	✓	40,87 €
CHC5-12/SS/B	M5	0,80	12	-	8,5	5	4	500	✓	43,40 €
CHC5-16/SS/B	M5	0,80	16	-	8,5	5	4	500	✓	49,47 €
CHC5-20/SS/B	M5	0,80	20	-	8,5	5	4	500	✓	56,78 €
CHC5-25/SS/B	M5	0,80	25	-	8,5	5	4	500	✓	54,73 €
CHC5-30/SS/B	M5	0,80	30	22	8,5	5	4	500	✓	72,05 €
CHC5-35/SS/B	M5	0,80	35	22	8,5	5	4	500	✓	70,06 €
CHC5-40/SS/B	M5	0,80	40	22	8,5	5	4	500	✓	94,32 €
CHC5-50/SS/B	M5	0,80	50	22	8,5	5	4	200	✓	49,33 €
CHC6-8/SS/B	M6	1,00	8	-	10,0	6	5	500	✓	53,81 €
CHC6-10/SS/B	M6	1,00	10	-	10,0	6	5	500	✓	61,74 €
CHC6-12/SS/B	M6	1,00	12	-	10,0	6	5	500	✓	68,59 €
CHC6-16/SS/B	M6	1,00	16	-	10,0	6	5	500	✓	75,55 €
CHC6-20/SS/B	M6	1,00	20	-	10,0	6	5	500	✓	58,62 €
CHC6-25/SS/B	M6	1,00	25	-	10,0	6	5	500	✓	68,41 €
CHC6-30/SS/B	M6	1,00	30	-	10,0	6	5	500	✓	96,69 €
CHC6-35/SS/B	M6	1,00	35	24	10,0	6	5	500	✓	61,85 €
CHC6-40/SS/B	M6	1,00	40	24	10,0	6	5	500	-	67,36 €
CHC6-50/SS/B	M6	1,00	50	24	10,0	6	5	500	✓	164,20 €
CHC6-60/SS/B	M6	1,00	60	24	10,0	6	5	500	-	125,30 €
CHC6-80/SS/B	M6	1,00	80	24	10,0	6	5	100	✓	69,07 €
CHC6-100/SS/B	M6	1,00	100	24	10,0	6	5	100	✓	91,29 €
CHC8-10/SS/B	M8	1,25	10	-	13,0	8	6	200	-	41,65 €
CHC8-16/SS/B	M8	1,25	16	-	13,0	8	6	200	✓	55,57 €
CHC8-20/SS/B	M8	1,25	20	-	13,0	8	6	200	✓	57,30 €
CHC8-25/SS/B	M8	1,25	25	-	13,0	8	6	200	✓	63,54 €
CHC8-30/SS/B	M8	1,25	30	-	13,0	8	6	200	✓	66,34 €
CHC8-35/SS/B	M8	1,25	35	-	13,0	8	6	200	✓	84,75 €
CHC8-40/SS/B	M8	1,25	40	28	13,0	8	6	200	✓	104,25 €
CHC8-50/SS/B	M8	1,25	50	28	13,0	8	6	200	✓	109,58 €
CHC8-60/SS/B	M8	1,25	60	28	13,0	8	6	200	✓	132,72 €
CHC8-80/SS/B	M8	1,25	80	28	13,0	8	6	200	-	203,17 €
CHC10-20/SS/B	M10	1,50	20	-	16,0	10	8	100	✓	39,19 €
CHC10-25/SS/B	M10	1,50	25	-	16,0	10	8	100	✓	50,42 €
CHC10-30/SS/B	M10	1,50	30	-	16,0	10	8	100	✓	60,08 €
CHC10-40/SS/B	M10	1,50	40	-	16,0	10	8	100	✓	70,33 €
CHC10-50/SS/B	M10	1,50	50	32	16,0	10	8	100	-	41,99 €

*Dans la limite du disponible - Dimensions en mm

Fax 0 825 88 6000
Service 0,15 € / min
+ prix appel

cial2@hpceurope.com

HPC

Tome ① 2016

① 425