



- Se monte dans les alésages des réducteurs CHM et CHMR
- Arbre acier

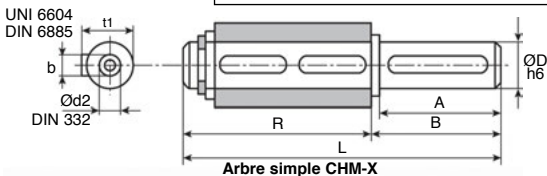

Arbre simple CHM-X

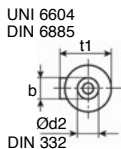

Arbre double CHM-DX

REMISES A

Qté	1+	6+	20+	40+
Rem.	Prix	-15%	-20%	Sur demande

REMISES B

Qté	1+	2+	6+	15+
Rem.	Prix	-5%	-15%	Sur demande

Références	ØD h6	A	B	b	t1	R	L	Ød2	Masse (kg)	Stock*	Prix Uni.
Arbre simple											
CHM30-X	14	30	32,5	5	16,0	69,5	102	M6x16	0,14	✓ A	14,23 €
CHM40-X	18	40	43,0	6	20,5	85,0	128	M6x16	0,27	✓ A	16,79 €
CHM50-X	25	50	53,5	8	28,0	99,5	153	M10x22	0,60	✓ A	19,31 €
CHM63-X	25	50	53,5	8	28,0	119,5	173	M10x22	0,67	✓ A	21,49 €
CHM75-X	28	60	63,5	8	31,0	128,5	192	M10x22	0,94	✓ B	23,99 €
CHM90-X	35	80	84,5	10	38,0	149,5	234	M12x28	1,79	✓ B	35,73 €
CHM110-X	42	80	84,5	12	45,0	164,5	249	M16x35	2,70	- B	40,43 €
Arbre double											
CHM30-DX	14	30	32,5	5	16,0	63,0	128	M6x16	0,16	✓ A	19,31 €
CHM40-DX	18	40	43,0	6	20,5	78,0	164	M6x16	0,34	✓ A	21,49 €
CHM50-DX	25	50	53,5	8	28,0	92,0	199	M10x22	0,75	✓ A	23,99 €
CHM63-DX	25	50	53,5	8	28,0	112,0	219	M10x22	0,84	- A	26,17 €
CHM75-DX	28	60	63,5	8	31,0	120,0	247	M10x22	1,20	✓ B	28,49 €
CHM90-DX	35	80	84,5	10	38,0	140,0	309	M12x28	2,50	✓ B	42,06 €
CHM110-DX	42	80	84,5	12	45,0	155,0	324	M16x35	3,44	- B	50,03 €

*Dans la limite du disponible - Dimensions en mm