

 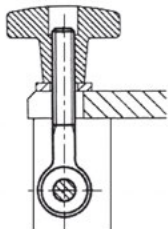


- Chape à oeil
- Inox
- Selon DIN 444 forme B

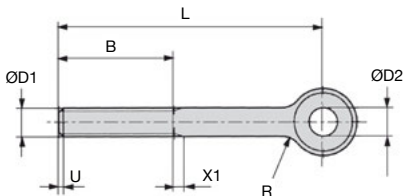

Exemple d'application



U = max 2 pas  
X1 conforme à la DIN76

**REMISES**

Qté	1+	15+	20+	25+	30+	50+
Rem.	Prix	-5%	-10%	-15%	-20%	Sur demande

Références	L	ØD1	ØD2	ØD3	B	S	R	Poids (kg)	Stock*	Prix Uni. 1 à 14
CMA1-05-50/SS	50	M5	5	12	16	6	2,5	0,011	✓	12,18 €
CMA1-06-50/SS	50	M6	6	14	18	7	4	0,016	✓	9,66 €
CMA1-06-75/SS	75	M6	6	14	18	7	4	0,021	-	10,99 €
CMA1-08-50/SS	50	M8	8	18	22	9	4	0,030	✓	11,07 €
CMA1-08-75/SS	75	M8	8	18	22	9	4	0,040	✓	12,60 €
CMA1-10-75/SS	75	M10	10	20	26	12	4	0,055	✓	12,96 €
CMA1-10-100/SS	100	M10	10	20	26	12	4	0,070	✓	13,53 €
CMA1-12-75/SS	75	M12	12	25	30	14	6	0,085	✓	15,92 €
CMA1-12-100/SS	100	M12	12	25	30	14	6	0,100	✓	17,45 €
CMA1-12-120/SS	120	M12	12	25	30	14	6	0,124	-	18,45 €
CMA1-12-130/SS	130	M12	12	25	36	14	6	0,135	✓	19,05 €
CMA1-16-130/SS	130	M16	16	32	44	17	6	0,244	-	34,22 €

\*Dans la limite du disponible - Dimensions en mm