
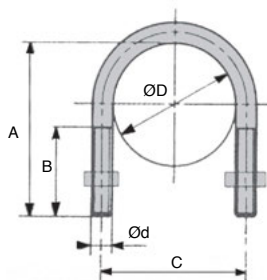
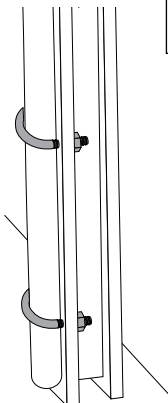


- Livré avec 2 écrous

- Matière :

Inox 304

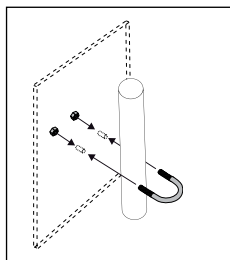

REMISES

Qté	1+	101+	201+	301+	401+
Rem. Prix	-5%	-10%	-15%	Sur demande	

Références	Pour tube		Filet Ød	A (mm)	B (mm)	C (mm)	Stock*	Prix Uni. 1 à 100
	ØExtérieur ØD	cote Pouce d						
EIM013	13	1/4	M6	28	20	19	-	1,19 €
EIM017	17	3/8	M6	36	22	23	-	1,44 €
EIM021	21	1/2	M6	40	20	27	✓	1,51 €
EIM027	27	3/4	M8	50	30	35	✓	2,77 €
EIM034	34	1	M8	55	30	42	✓	3,03 €
EIM042	42	1 1/4	M8	68	35	50	✓	3,43 €
EIM049	49	1 1/2	M8	70	35	57	✓	3,55 €
EIM060	60	2	M8	80	35	68	✓	3,68 €
EIM076	76	2 1/2	M8	110	45	84	-	4,43 €
EIM089	89	3	M10	115	45	99	-	7,96 €
EIM114	114	4	M10	156	55	124	-	8,98 €

*Dans la limite du disponible - Dimensions en mm