


Taroudage M3 à M12

EMSH
EMS-B

- **Ecrou moleté monobloc**

- Matière :


Inox 18.9

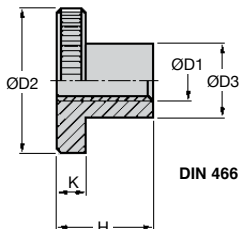

DIN 466



Version haute EMS-H

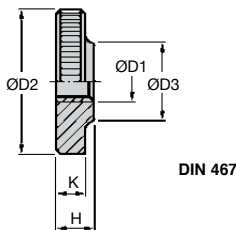

DIN 467



Version basse EMS-B

REMISES

Qté	1+	6+	20+	40+	60+	101+
Rem.	Prix -10%	-15%	-20%	-25%	Sur demande	

Références	ØD1	ØD2	ØD3	H	K	Stock*	Prix Uni. 1 à 5
Version haute							
EMS-3H	M3	12	6	7,5	2,5	✓	1,08 €
EMS-4H	M4	16	8	9,5	3,5	✓	1,64 €
EMS-5H	M5	20	10	11,5	4,0	✓	1,91 €
EMS-6H	M6	24	12	15,0	5,0	✓	2,99 €
EMS-8H	M8	30	16	18,0	6,0	✓	6,56 €
EMS-10H	M10	36	20	23,0	8,0	✓	10,67 €
EMS-12H	M12	36	20	23,0	8,0	✓	18,05 €
Version basse							
EMS-4B	M4	16	8	4,0	3,5	✓	1,26 €
EMS-5B	M5	20	10	5,0	4,0	✓	1,68 €
EMS-6B	M6	24	12	6,0	5,0	✓	2,65 €
EMS-8B	M8	30	16	8,0	6,0	✓	6,44 €
EMS-10B	M10	36	20	10,0	8,0	✓	11,59 €
EMS-12B	M12	36	20	10,0	8,0	✓	15,25 €

*Dans la limite du disponible - Dimensions en mm