

Embout rapide **inox** pour câble



ERCss
ERLss

Chape et embout à œil



- Embouts de tringlerie à sertissage manuel

- Matière :


Inox 316

Avantage

- Montage manuel rapide

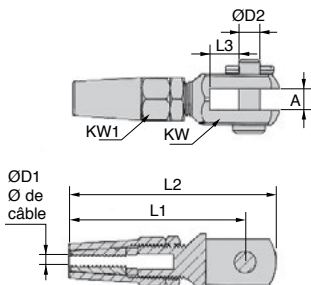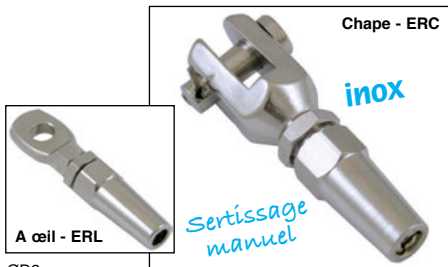

Chape - ERC

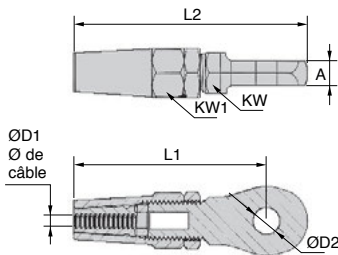

A œil - ERL

**NOUVELLES
REMISES**

REMISES

Qté	1+	4+	10+	15+
Rem.	Prix -10%	-20%	Sur demande	


Références	ØD1	ØD2	A	L1	L2	L3	KW	KW1	Masse (g)	Stock*	Prix Uni.
											1 à 3
Chape											
ERC3-6/SS	3	6	6,25	49,0	57,0	8,0	12	14	40	✓	29,22 €
ERC4-8/SS	4	8	7,90	60,5	71,4	8,3	14	19	80	✓	34,38 €
ERC5-10/SS	5	10	9,70	69,0	79,0	10,0	16	22	120	-	40,63 €
ERC6-12/SS	6	12	11,00	81,0	93,0	12,0	19	27	210	✓	51,12 €
ERC8-14/SS	8	14	13,00	106,0	120,0	15,0	24	30	376	-	70,33 €
Embout à œil											
ERL3-6/SS	3	6	6	48	57	-	10	12	34	✓	30,65 €
ERL4-8/SS	4	8	7	56	69	-	14	14	62	-	34,97 €
ERL5-10/SS	5	10	8	66	82	-	14	16	88	-	41,28 €
ERL6-13/SS	6	13	9	83	100	-	17	19	154	-	50,40 €
ERL8-14/SS	8	14	10	102	123	-	19	24	278	-	66,41 €

*Dans la limite du disponible - Dimensions en mm

- Embouts de tringlerie à sertissage manuel
- Matière : inox 316

Avantage

- Montage manuel rapide

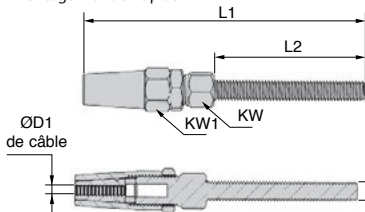

**NOUVELLES
REMISES**

REMISES

Qté	1+	4+	10+	15+
Rem. Prix	-10%	-10%	-20%	Sur demande

Références	ØD1	ØG	L1	L2	KW	KW1	Masse (g)	Stock*	Prix Uni. 1 à 3
ERF3-5-41/SS	3	M5	82	41	10	12	32	✓	33,11 €
ERF3-6-47/SS	3	M6	88	47	10	12	36	✓	33,30 €
ERF4-6-47/SS	4	M6	96	47	12	14	54	✓	37,15 €
ERF4-8-56/SS	4	M8	106	56	12	14	62	✓	38,17 €
ERF5-8-56/SS	5	M8	112	56	14	16	84	-	44,55 €
ERF5-10-62/SS	5	M10	118	62	13	16	96	-	45,01 €
ERF6-10-62/SS	6	M10	124	62	16	19	136	-	53,34 €
ERF6-12-79/SS	6	M12	144	79	16	19	164	-	59,25 €
ERF8-14-88/SS	8	M14	168	88	19	24	298	-	81,02 €
ERF8-16-99/SS	8	M16	180	99	19	24	338	-	81,95 €

*Dans la limite du disponible - Dimensions en mm

Schéma de montage

