

# Embout rapide pour câble



ERCss  
ERLss

Chape et embout à œil






- Embouts de tringlerie à sertissage manuel

- Matière :

Inox 316

**Avantage**

 - Montage manuel rapide

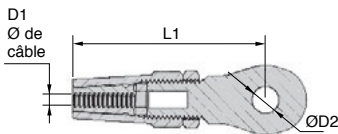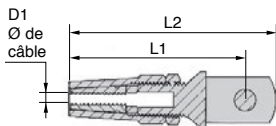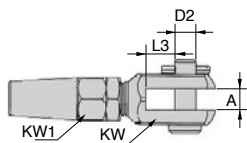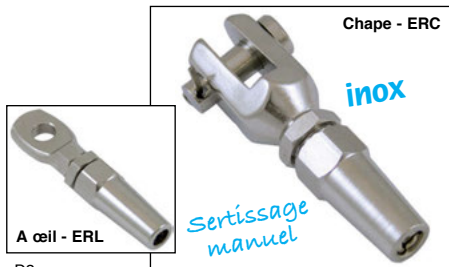

Chape - ERC

A œil - ERL



## REMISES

Qté	1+	6+	20+	50+
Rem. Prix	-10%	-10%	-20%	Sur demande

Références	ØD1	ØD2	A	L1	L2	L3	KW	KW1	Masse (g)	Stock*	Prix Uni. 1 à 5
<b>Chape</b>											
ERC3-6/SS	3	6	6,25	49,0	57,0	8,0	12	14	40	✓	26,74 €
ERC4-8/SS	4	8	7,90	60,5	71,4	8,3	14	19	80	✓	31,44 €
ERC5-10/SS	5	10	9,70	69,0	79,0	10,0	16	22	120	✓	37,16 €
ERC6-12/SS	6	12	11,00	81,0	93,0	12,0	19	27	210	✓	46,74 €
ERC8-14/SS	8	14	13,00	106,0	120,0	15,0	24	30	376	✓	64,29 €
<b>Embout à œil</b>											
ERL3-6/SS	3	6	6	48	57	-	10	12	34	✓	28,03 €
ERL4-8/SS	4	8	7	56	69	-	14	14	62	-	31,99 €
ERL5-10/SS	5	10	8	66	82	-	14	16	88	-	37,75 €
ERL6-13/SS	6	13	9	83	100	-	17	19	154	✓	46,08 €
ERL8-14/SS	8	14	10	102	123	-	19	24	278	-	60,73 €

\*Dans la limite du disponible - Dimensions en mm