


- Embouts de tringlerie à sertissage manuel
- Matière : inox 316

Avantage

- Montage manuel rapide

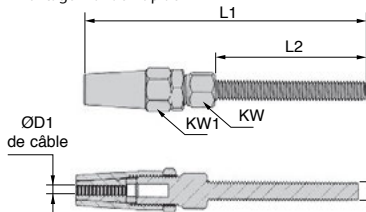

REMISES

Qté	1+	6+	20+	50+
Rem. Prix	-10%	-20%	Sur demande	

Références	ØD1	ØG	L1	L2	KW	KW1	Masse (g)	Stock*	Prix Uni. 1 à 5
ERF3-5-41/SS	3	M5	82	41	10	12	32	✓	30,28 €
ERF3-6-47/SS	3	M6	88	47	10	12	36	✓	30,45 €
ERF4-6-47/SS	4	M6	96	47	12	14	54	✓	33,98 €
ERF4-8-56/SS	4	M8	106	56	12	14	62	✓	34,92 €
ERF5-8-56/SS	5	M8	112	56	14	16	84	✓	40,73 €
ERF5-10-62/SS	5	M10	118	62	13	16	96	✓	41,16 €
ERF6-10-62/SS	6	M10	124	62	16	19	136	-	48,77 €
ERF6-12-79/SS	6	M12	144	79	16	19	164	-	54,16 €
ERF8-14-88/SS	8	M14	168	88	19	24	298	-	74,06 €
ERF8-16-99/SS	8	M16	180	99	19	24	338	-	74,93 €

*Dans la limite du disponible - Dimensions en mm

Schéma de montage

