


- Matière : **Inox 303**
- Longueur standard de 300mm à 1000mm cf. colonne L
- Tolérance diam. ext. h6
- Rectitude 0,01/300mm
- Etat de surface Ra 0,4

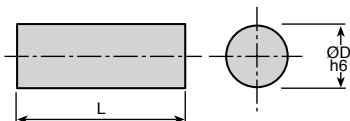

### REMISES

Qté	1+	6+	20+	40+	60+	100+
Rem.	Prix	-10%	-15%	-20%	-25%	Sur demande

Références	ØD	L	Stock*	Prix Uni. 1 à 5	Références	ØD	L	Stock*	Prix Uni. 1 à 5
GR2.992-6	2,992	600	✓	25,55 €	GR9.993-10	9,993	1000	-	123,93 €
GR3.000-6	3,000	600	✓	16,06 €	GR10.000-4	10,000	400	✓	40,56 €
GR3.992-6	3,992	600	✓	21,34 €	GR10.000-9	10,000	900	-	104,03 €
GR3.999-6	3,999	600	✓	31,86 €	GR10.000-10	10,000	1000	-	123,93 €
GR4.991-9	4,991	900	✓	36,71 €	GR11.991-4	11,991	400	-	54,91 €
GR5.000-6	5,000	600	✓	20,15 €	GR11.993-1	11,993	1000	-	161,39 €
GR5.993-6	5,993	600	✓	42,03 €	GR12.000-4	12,000	400	✓	54,91 €
GR5.992-9	5,992	900	-	39,79 €	GR12.000-9	12,000	900	-	142,69 €
GR6.000-6	6,000	600	✓	39,79 €	GR12.000-10	12,000	1000	✓	164,29 €
GR6.000-9	6,000	900	✓	39,79 €	GR12.993-4	12,993	400	-	57,36 €
GR7.000-6	7,000	600	✓	30,30 €	GR12.993-9	12,993	900	-	sur demande
GR7.000-9	7,000	900	-	45,30 €	GR13.993-9	13,993	900	-	167,86 €
GR7.993-6	7,993	600	✓	37,34 €	GR14.991-9	14,991	900	-	223,20 €
GR7.993-9	7,993	900	-	55,94 €	GR16.000-9	16,000	900	-	230,61 €
GR8.000-6	8,000	600	✓	35,45 €	GR19.992-9	19,992	900	✓	295,35 €
GR8.992-9	8,992	900	-	99,85 €	GR25.000-9	25,000	900	-	411,82 €
GR9.992-9	9,992	900	✓	104,76 €	GR29.992-9	29,992	900	-	560,33 €

\*Dans la limite du disponible - Dimensions en mm