
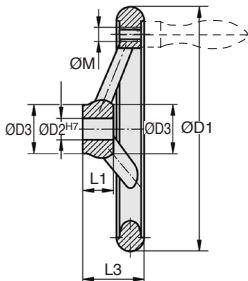
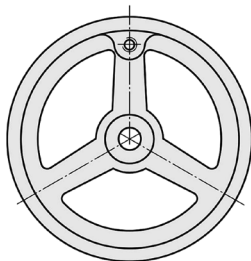


- **Volant seul**
- Selon DIN950
- Version avec et sans rainure de clavette DIN6885-1
- Matière :
Inox 1.4401 (316)
Finition : décolleté et polie

Accessoire

- Voir poignée tournante **HLUMss**

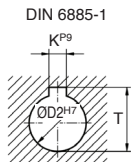

REMISES

Qté	1+	3+	5+	10+
Rem. Prix	-5%	-10%	Sur demande	

Références	ØD1	ØD2	ØD3	L1	L3	M	K	T	Nbe de rayons	Prix Uni. 1 à 2
Sans rainure de clavette										
HLU100-10/SS	100	10	26	17	33	M6	-	-	3	51,84 €
HLU125-12/SS	125	12	28	18	36	M8	-	-	3	74,35 €
HLU140-14/SS	140	14	30	19	39	M8	-	-	3	95,92 €
HLU160-16/SS	160	16	32	20	40	M10	-	-	3	109,60 €
HLU200-18/SS	200	18	38	24	45	M10	-	-	3	192,40 €
Avec rainure de clavette										
HLU100-10K/SS	100	10	26	17	33	M6	3	11,4	3	54,45 €
HLU125-12K/SS	125	12	28	18	36	M8	4	13,8	3	76,96 €
HLU140-14K/SS	140	14	30	19	39	M8	5	16,3	3	98,56 €
HLU160-16K/SS	160	16	32	20	40	M10	5	18,3	3	112,22 €
HLU200-18K/SS	200	18	38	24	45	M10	6	20,8	3	196,25 €

Dimensions en mm