


Entretoise hexagonale



HS

Inox 303

- Colonne femelle/femelle
- Matière :
Inox 303
- Conditionnées par lot

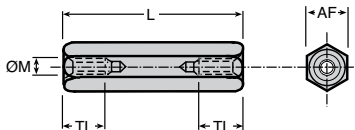

REMISES

Nb. lot	1+	5+	20+	100+
Rem.	Prix	-20%	-30%	Sur demande

Références	Filetage ØM	L	TL	AF	Qté par lot	Stock*	Prix Uni. par lot
HS3-5/B	M3	5	5	5,5	20	✓	14,77 €
HS3-8/B	M3	8	8	5,5	20	-	15,62 €
HS3-10/B	M3	10	10	5,5	20	✓	15,94 €
HS3-12/B	M3	12	12	5,5	20	✓	17,64 €
HS3-15/B	M3	15	15	5,5	20	✓	19,42 €
HS3-18/B	M3	18	18	5,5	20	✓	22,03 €
HS3-20/B	M3	20	20	5,5	20	✓	24,17 €
HS3-25/B	M3	25	10	5,5	20	-	25,45 €
HS3-35/B	M3	35	10	5,5	20	✓	28,27 €
HS3-40/B	M3	40	10	5,5	20	-	28,98 €
HS3-45/B	M3	45	10	5,5	20	-	29,80 €
HS4-5/B	M4	5	5	7,0	20	-	17,48 €
HS4-8/B	M4	8	8	7,0	20	-	19,05 €
HS4-10/B	M4	10	10	7,0	20	✓	20,86 €
HS4-12/B	M4	12	12	7,0	20	✓	22,35 €
HS4-15/B	M4	15	15	7,0	20	-	25,03 €
HS4-18/B	M4	18	18	7,0	20	-	27,22 €
HS4-20/B	M4	20	20	7,0	20	✓	27,71 €
HS4-25/B	M4	25	10	7,0	20	✓	28,13 €

*Dans la limite du disponible - Dimensions en mm