
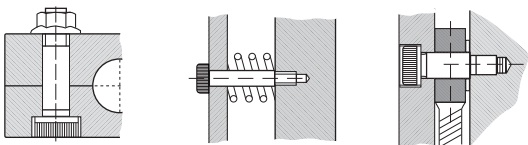
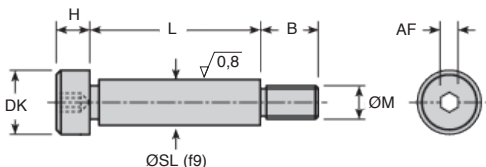


- Fonction de centrage et de serrage
- Epaulement rectifié, tolérance f9
- Matière :
inox A2

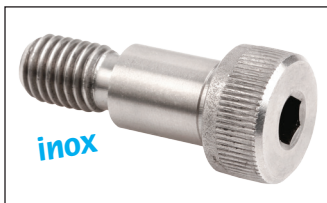

REMISES

Qté	1+	5+	10+
Rem.	Prix	-5%	Sur demande

Références	Filetage		L	ØSL (f9)	B	DK	H	AF	Prix Uni. 1 à 4
	ØM	Pas							
HSS5-10/SS/B	M5	0,80	10	6	9,50	10,22	4,5	3	45,85 €
HSS5-12/SS/B	M5	0,80	12	6	9,50	10,22	4,5	3	45,96 €
HSS5-16/SS/B	M5	0,80	16	6	9,50	10,22	4,5	3	47,66 €
HSS5-20/SS/B	M5	0,80	20	6	9,50	10,22	4,5	3	53,64 €
HSS5-25/SS/B	M5	0,80	25	6	9,50	10,22	4,5	3	62,09 €
HSS5-30/SS/B	M5	0,80	30	6	9,50	10,22	4,5	3	64,44 €
HSS5-40/SS/B	M5	0,80	40	6	9,50	10,22	4,5	3	70,65 €

Dimensions en mm

REMISES

Qté	1+	5+	10+
Rem.	Prix	-5%	Sur demande

Références	Filetage		ØSL					AF		Prix Uni. 1 à 4
	ØM	Pas	L	(f9)	B	DK	H	AF		
HSS6-12/SS/B	M6	1,00	12	8	11,00	13,27	5,5	4	55,09 €	
HSS6-16/SS/B	M6	1,00	16	8	11,00	13,27	5,5	4	54,07 €	
HSS6-20/SS/B	M6	1,00	20	8	11,00	13,27	5,5	4	62,47 €	
HSS6-25/SS/B	M6	1,00	25	8	11,00	13,27	5,5	4	68,48 €	
HSS6-30/SS/B	M6	1,00	30	8	11,00	13,27	5,5	4	69,31 €	
HSS6-40/SS/B	M6	1,00	40	8	11,00	13,27	5,5	4	73,66 €	
HSS6-50/SS/B	M6	1,00	50	8	11,00	13,27	5,5	4	83,27 €	
HSS8-16/SS/B	M8	1,25	16	10	13,00	16,27	7	5	58,00 €	
HSS8-20/SS/B	M8	1,25	20	10	13,00	16,27	7	5	61,12 €	
HSS8-25/SS/B	M8	1,25	25	10	13,00	16,27	7	5	67,07 €	
HSS8-30/SS/B	M8	1,25	30	10	13,00	16,27	7	5	83,22 €	
HSS8-40/SS/B	M8	1,25	40	10	13,00	16,27	7	5	76,92 €	
HSS8-50/SS/B	M8	1,25	50	10	13,00	16,27	7	5	86,15 €	
HSS8-60/SS/B	M8	1,25	60	10	13,00	16,27	7	5	94,95 €	
HSS8-70/SS/B	M8	1,25	70	10	13,00	16,27	7	5	115,64 €	
HSS8-80/SS/B	M8	1,25	80	10	13,00	16,27	7	5	109,79 €	
HSS10-16/SS/B	M10	1,50	16	12	16,00	18,27	9	6	45,46 €	
HSS10-20/SS/B	M10	1,50	20	12	16,00	18,27	9	6	50,67 €	
HSS10-25/SS/B	M10	1,50	25	12	16,00	18,27	9	6	48,66 €	
HSS10-30/SS/B	M10	1,50	30	12	16,00	18,27	9	6	53,62 €	
HSS10-40/SS/B	M10	1,50	40	12	16,00	18,27	9	6	55,83 €	
HSS10-50/SS/B	M10	1,50	50	12	16,00	18,27	9	6	58,49 €	
HSS10-60/SS/B	M10	1,50	60	12	16,00	18,27	9	6	61,40 €	
HSS10-70/SS/B	M10	1,50	70	12	16,00	18,27	9	6	72,66 €	
HSS10-80/SS/B	M10	1,50	80	12	16,00	18,27	9	6	68,81 €	
HSS10-100/SS/B	M10	1,50	100	12	16,00	18,27	9	6	136,06 €	
HSS12-30/SS/B	M12	1,75	30	16	18,00	24,33	11	8	89,48 €	
HSS12-40/SS/B	M12	1,75	40	16	18,00	24,33	11	8	89,39 €	
HSS12-50/SS/B	M12	1,75	50	16	18,00	24,33	11	8	124,13 €	
HSS12-60/SS/B	M12	1,75	60	16	18,00	24,33	11	8	151,32 €	
HSS12-70/SS/B	M12	1,75	70	16	18,00	24,33	11	8	121,47 €	
HSS12-80/SS/B	M12	1,75	80	16	18,00	24,33	11	8	277,97 €	
HSS12-100/SS/B	M12	1,75	100	16	18,00	24,33	11	8	179,57 €	
HSS16-40/SS/B	M16	2,00	40	20	22,00	30,33	14	10	123,79 €	
HSS16-50/SS/B	M16	2,00	50	20	22,00	30,33	14	10	182,37 €	
HSS16-60/SS/B	M16	2,00	60	20	22,00	30,33	14	10	148,46 €	
HSS16-70/SS/B	M16	2,00	70	20	22,00	30,33	14	10	166,80 €	
HSS16-80/SS/B	M16	2,00	80	20	22,00	30,33	14	10	211,26 €	