
 


- Liaison par obstacle
- Forme A
- Nécessite l'usinage de rainures de clavette
- Matière : inox 316 Ti (60 daN/mm²) (inox 1.4571)
- Vendu par multiple, nous contacter

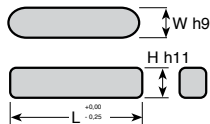

Mémo du dessinateur

Diamètre d'alésage ou d'arbre de Ø jusqu'à Ø (inclus)	Rainure de clavette (mm)		
	W	H	p
Ø6 - Ø8	2	1,07	1,25
Ø8 - Ø10	3	1,50	1,85
Ø10 - Ø12	4	1,86	2,55
Ø12 - Ø17	5	2,35	3,05
Ø17 - Ø22	6	2,83	3,55
Ø22 - Ø30	8	3,34	4,10
Ø30 - Ø38	10	3,34	5,10
Ø38 - Ø44	12	3,35	5,10
Ø44 - Ø50	14	3,80	5,50



REMISES

Qté	1+	6+	20+	50+	100+	200+
Rem.	Prix -15%-45%-55%-65% Sur demande					

Références	Largeur W (h9)	Hauteur H (h11)	Longueur L	Stock*	Prix Uni. 1 à 5
KK2-20SS	2	2	20	✓	3,86 €
KK3-10SS	3	3	10	✓	1,36 €
KK3-20SS	3	3	20	✓	1,49 €
KK4-10SS	4	4	10	✓	1,66 €
KK4-12SS	4	4	12	✓	1,03 €
KK4-18SS	4	4	18	✓	1,71 €
KK4-20SS	4	4	20	✓	1,84 €
KK4-25SS	4	4	25	✓	1,94 €
KK5-10SS	5	5	10	✓	1,78 €
KK5-20SS	5	5	20	✓	2,11 €
KK5-25SS	5	5	25	✓	2,24 €
KK5-30SS	5	5	30	✓	2,55 €
KK6-10SS	6	6	10	✓	2,11 €
KK6-20SS	6	6	20	✓	2,54 €
KK6-25SS	6	6	25	✓	2,84 €
KK6-30SS	6	6	30	✓	3,29 €
KK8-7-20SS	8	7	20	✓	3,41 €
KK8-7-25SS	8	7	25	✓	3,86 €
KK8-7-30SS	8	7	30	✓	4,44 €
KK8-7-35SS	8	7	35	✓	4,82 €
KK10-8-20SS	10	8	20	✓	4,59 €
KK10-8-25SS	10	8	25	✓	5,31 €
KK10-8-30SS	10	8	30	✓	6,19 €
KK10-8-35SS	10	8	35	✓	6,77 €
KK12-8-20SS	12	8	20	-	7,40 €
KK12-8-25SS	12	8	25	✓	7,35 €
KK12-8-30SS	12	8	30	✓	7,40 €
KK12-8-35SS	12	8	35	✓	7,95 €

*Dans la limite du disponible - Dimensions en mm