 



Acier C45 ou Inox 316

KS
KSs

- Barreaux à clavette à recouper à la longueur désirée
- Selon DIN6880
- Matières

Acier C45 (résistance à la rupture 50kg/mm² mini)
Inox 316Ti (X6CrNiMoTi17-12-2)

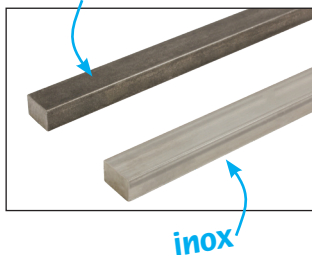

REMISES

Qté	1+	6+	20+
Rem. Prix	-15%	Sur demande	

Références		W	H	L	Stock*	Stock*	Prix Uni. 1 à 5	
Acier	Inox	(h9)	(h11)	(mm)	Acier	Inox	Acier	Inox
KS2-500	-	2	2	500	✓		5,92 €	-
KS3-500	-	3	3	500	✓		5,10 €	-
KS4-500	-	4	4	500	✓		6,12 €	-
KS5-500	KS5-500/SS	5	5	500	✓	✓	7,86 €	57,97 €
KS6-500	KS6-500/SS	6	6	500	✓	-	10,05 €	59,75 €
KS8-500	-	8	8	500	✓		11,67 €	-
KS87-500	KS87-500/SS	8	7	500	✓	-	10,04 €	84,71 €
KS10-500	-	10	10	500	✓		17,06 €	-
KS108-500	KS108-500/SS	10	8	500	✓	-	14,28 €	118,32 €
KS12-500	-	12	12	500	-		22,37 €	-
KS128-500	KS128-500/SS	12	8	500	✓	-	12,83 €	142,40 €
KS14-500	-	14	14	500	-		26,41 €	-
KS149-500	KS149-500/SS	14	9	500	✓	-	16,84 €	193,80 €
KS1610-500	KS1610-500/SS	16	10	500	✓	-	21,36 €	240,16 €
KS1811-500	KS1811-500/SS	18	11	500	✓	-	26,44 €	287,13 €
KS2012-500	-	20	12	500	✓		30,05 €	-
KS2214-500	KS2214-500/SS	22	14	500	-	-	38,96 €	431,90 €
KS2514-500	-	25	14	500	✓		44,22 €	-

*Dans la limite du disponible - Dimensions en mm