 



- Barreaux à clavette à recouper à la longueur désirée
- Selon DIN6880
- Matières
 - Acier C45 (résistance à la rupture 50kg/mm² mini)
 - Inox 316Ti (X6CrNiMoTi17-12-2)

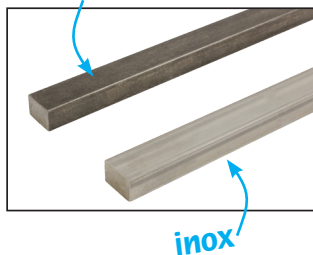

REMISES

Qté	1+	6+	20+
Rem.	Prix	-15%	Sur demande

Références		W (h9)	H (h11)	L (mm)	Stock*	Stock*	Prix Uni. 1 à 5	
Acier	Inox				Acier	Inox	Acier	Inox
KS2-500	-	2	2	500	-	-	5,80 €	-
KS3-500	-	3	3	500	-	-	5,00 €	-
KS4-500	-	4	4	500	-	-	6,00 €	-
KS5-500	KS5-500/SS	5	5	500	-	-	7,70 €	56,84 €
KS6-500	KS6-500/SS	6	6	500	-	-	9,85 €	58,58 €
KS8-500	-	8	8	500	-	-	11,44 €	-
KS87-500	KS87-500/SS	8	7	500	-	-	9,84 €	83,04 €
KS10-500	-	10	10	500	-	-	16,72 €	-
KS108-500	KS108-500/SS	10	8	500	-	-	14,00 €	115,99 €
KS12-500	-	12	12	500	-	-	21,93 €	-
KS128-500	KS128-500/SS	12	8	500	-	-	12,57 €	139,59 €
KS14-500	-	14	14	500	-	-	25,89 €	-
KS149-500	KS149-500/SS	14	9	500	-	-	16,50 €	189,98 €
KS1610-500	KS1610-500/SS	16	10	500	-	-	20,94 €	235,43 €
KS1811-500	KS1811-500/SS	18	11	500	-	-	25,92 €	281,48 €
KS2012-500	-	20	12	500	-	-	29,46 €	-
KS2214-500	KS2214-500/SS	22	14	500	-	-	38,19 €	423,38 €
KS2514-500	-	25	14	500	-	-	43,35 €	-

*Dans la limite du disponible - Dimensions en mm