

Entretoise hexagonale

Ac **Stock**

MPE


Acier

- Colonne mâle/femelle

- Matière :

Acier finition électrolyse zingué Zn3-5Bl

- Conditionnées par lot

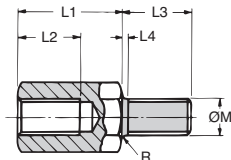

REMISES

Nb. lot	1+	5+	20+	100+
Rem.	Prix	-20%	-30%	Sur demande

Références	Filetage ØM	L1	L2	L3	L4	AF	R	Qté par lot	Stock*	Prix Uni. par lot
MPE3-5/B	M3	5	3	8	0,90	5	0,10	20	✓	4,21 €
MPE3-8/B	M3	8	4	8	0,90	5	0,10	20	✓	5,39 €
MPE3-10/B	M3	10	6	8	0,90	5	0,10	20	✓	5,80 €
MPE3-12/B	M3	12	8	8	0,90	5	0,10	20	✓	5,87 €
MPE3-15/B	M3	15	8	8	0,90	5	0,10	20	✓	6,05 €
MPE3-18/B	M3	18	8	8	0,90	5	0,10	20	✓	6,27 €
MPE3-20/B	M3	20	8	8	0,90	5	0,10	20	✓	6,33 €
MPE3-25/B	M3	25	10	10	0,90	5	0,10	20	✓	7,28 €
MPE3-30/B	M3	30	10	10	0,90	5	0,10	20	✓	7,61 €
MPE3-35/B	M3	35	10	10	0,90	5	0,10	20	✓	7,95 €
MPE3-40/B	M3	40	10	10	0,90	5	0,10	20	✓	12,40 €
MPE3-45/B	M3	45	10	10	0,90	5	0,10	20	✓	13,48 €
MPE3-50/B	M3	50	10	10	0,90	5	0,10	20	✓	14,60 €
MPE3-55/B	M3	55	10	10	0,90	5	0,10	20	✓	15,36 €
MPE3-60/B	M3	60	10	10	0,90	5	0,10	20	-	16,25 €
MPE3-70/B	M3	70	10	10	0,90	5	0,10	20	-	17,61 €
MPE3-80/B	M3	80	10	10	0,90	5	0,10	20	-	18,69 €
MPE4-5/B	M4	5	3	8	1,20	7	0,20	20	✓	6,79 €
MPE4-8/B	M4	8	4	8	1,20	7	0,20	20	✓	7,28 €
MPE4-10/B	M4	10	6	8	1,20	7	0,20	20	✓	6,76 €
MPE4-12/B	M4	12	8	8	1,20	7	0,20	20	✓	7,28 €
MPE4-15/B	M4	15	8	8	1,20	7	0,20	20	✓	7,35 €
MPE4-18/B	M4	18	8	8	1,20	7	0,20	20	-	8,02 €

*Dans la limite du disponible - Dimensions en mm

Références	Filetage							Qté par lot	Stock*	Prix Uni. par lot
	ØM	L1	L2	L3	L4	AF	R			
MPE4-20/B	M4	20	8	8	1,20	7	0,20	20	✓	8,28 €
MPE4-25/B	M4	25	10	10	1,20	7	0,20	20	✓	9,72 €
MPE4-30/B	M4	30	10	10	1,20	7	0,20	20	✓	10,40 €
MPE4-35/B	M4	35	10	10	1,20	7	0,20	20	✓	11,06 €
MPE4-40/B	M4	40	10	10	1,20	7	0,20	20	✓	15,80 €
MPE4-45/B	M4	45	10	10	1,20	7	0,20	20	✓	15,80 €
MPE4-50/B	M4	50	10	10	1,20	7	0,20	20	✓	17,87 €
MPE4-55/B	M4	55	10	10	1,20	7	0,20	20	-	18,99 €
MPE4-60/B	M4	60	10	10	1,20	7	0,20	20	✓	20,07 €
MPE4-70/B	M4	70	10	10	1,20	7	0,20	20	✓	22,69 €
MPE4-80/B	M4	80	10	10	1,20	7	0,20	20	✓	24,49 €
MPE5-5/B	M5	5	3	8	1,40	8	0,20	20	-	10,89 €
MPE5-8/B	M5	8	4	8	1,40	8	0,20	20	-	10,89 €
MPE5-10/B	M5	10	6	8	1,40	8	0,20	20	✓	10,89 €
MPE5-12/B	M5	12	8	8	1,40	8	0,20	20	✓	11,34 €
MPE5-15/B	M5	15	8	8	1,40	8	0,20	20	✓	11,88 €
MPE5-18/B	M5	18	8	8	1,40	8	0,20	20	-	12,47 €
MPE5-20/B	M5	20	8	8	1,40	8	0,20	20	✓	12,98 €
MPE5-25/B	M5	25	10	10	1,40	8	0,20	20	✓	14,06 €
MPE5-30/B	M5	30	10	10	1,40	8	0,20	20	✓	14,97 €
MPE5-35/B	M5	35	10	10	1,40	8	0,20	20	✓	16,45 €
MPE5-40/B	M5	40	10	10	1,40	8	0,20	20	✓	17,91 €
MPE5-45/B	M5	45	10	10	1,40	8	0,20	20	✓	18,93 €
MPE5-50/B	M5	50	10	10	1,40	8	0,20	20	✓	20,03 €
MPE5-55/B	M5	55	10	10	1,40	8	0,20	20	-	21,13 €
MPE5-60/B	M5	60	10	10	1,40	8	0,20	20	✓	22,41 €
MPE5-70/B	M5	70	10	10	1,40	8	0,20	20	-	25,10 €
MPE5-80/B	M5	80	10	10	1,40	8	0,20	20	✓	29,38 €
MPE6-10/B	M6	10	6	12	2,10	10	0,25	20	✓	15,80 €
MPE6-12/B	M6	12	8	12	2,10	10	0,25	20	✓	15,91 €
MPE6-15/B	M6	15	8	12	2,10	10	0,25	20	✓	16,63 €
MPE6-18/B	M6	18	12	12	2,10	10	0,25	20	✓	17,11 €
MPE6-20/B	M6	20	13	12	2,10	10	0,25	20	✓	17,73 €
MPE6-25/B	M6	25	13	12	2,10	10	0,25	20	✓	19,31 €
MPE6-30/B	M6	30	13	12	2,10	10	0,25	20	✓	20,23 €
MPE6-35/B	M6	35	13	12	2,10	10	0,25	20	✓	21,13 €
MPE6-40/B	M6	40	13	12	2,10	10	0,25	20	✓	22,07 €
MPE6-45/B	M6	45	13	12	2,10	10	0,25	20	✓	23,08 €
MPE6-50/B	M6	50	13	12	2,10	10	0,25	20	✓	24,36 €
MPE6-55/B	M6	55	13	12	2,10	10	0,25	20	-	25,33 €
MPE6-60/B	M6	60	13	12	2,10	10	0,25	20	✓	26,24 €
MPE6-70/B	M6	70	13	12	2,10	10	0,25	20	✓	28,50 €
MPE6-80/B	M6	80	13	12	2,10	10	0,25	20	✓	30,37 €

*Dans la limite du disponible - Dimensions en mm