


Acier ou inox A2 et frein nylon

NINA
NIN

- Selon DIN 985
- Ecrou indesserrable
- Insert nylon
- Matières :
 - Acier zingué classe 6.8
 - Inox A2
- Conditionnés par lot

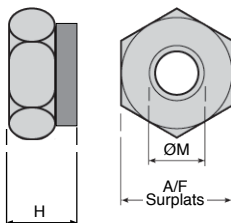

REMISES

Qté	1+	6+	11+
Rem.	Prix	-10%	Sur demande

Références	Taraudage ØM	Pas	A/F Surplats	H	Qté par lot	Stock*	Prix Uni. 1 à 5
Acier							
NINA-5/B	M5	0,80	8,0	5,0	500	✓	8,72 €
NINA-6/B	M6	1,00	10,0	6,0	500	✓	11,97 €
NINA-8/B	M8	1,25	13,0	8,0	200	✓	10,20 €
NINA-10/B	M10	1,50	17,0	10,0	200	✓	22,61 €
NINA-12/B	M12	1,75	19,0	12,0	200	✓	34,07 €
NINA-16/B	M16	2,00	24,0	16,0	100	-	37,67 €
NINA-20/B	M20	2,50	30,0	20,0	50	-	31,56 €
Inox							
NIN-3/B	M3	0,50	5,5	4,0	1000	✓	32,99 €
NIN-4/B	M4	0,70	7,0	5,0	1000	✓	31,40 €
NIN-5/B	M5	0,80	8,0	5,0	1000	✓	38,84 €
NIN-6/B	M6	1,00	10,0	6,0	500	✓	31,37 €
NIN-8/B	M8	1,25	13,0	8,0	200	✓	29,30 €
NIN-10/B	M10	1,50	17,0	10,0	200	✓	48,15 €
NIN-12/B	M12	1,75	19,0	12,0	100	✓	35,07 €
NIN-16/B	M16	2,00	24,0	16,0	50	✓	31,24 €
NIN-20/B	M20	2,50	30,0	20,0	25	-	71,96 €

*Dans la limite du disponible - Dimensions en mm