
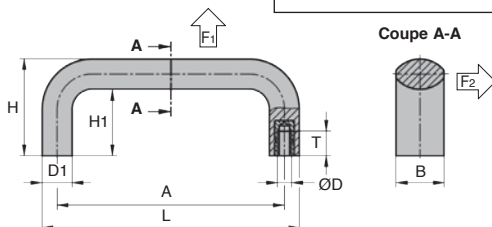


Poignée de manutention

Thermoplastique

PGM

- Poignée de préhension pour pousser et tirer
- Montage par l'arrière
- Matières :
Thermoplastique noir renforcé fibre de verre, insert taraudé en laiton

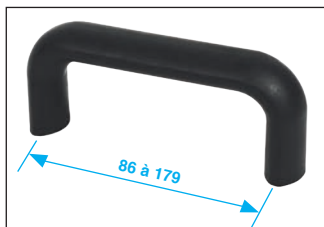

REMISES

Qté	1+	6+	20+	50+	100+	250+
Rem.	Prix	-5%	-10%	-15%	-20%	Sur demande

Références	A	B	ØD	D1	H	H1	L	T	F1 (N)	F2 (N)	Prix Uni. 1 à 5
PGM86-M5	86	20	M5	12,5	40	28	98,5	10	4000	1500	6,48 €
PGM86-M6	86	20	M6	12,5	40	28	98,5	9	4000	1500	6,81 €
PGM94-M5	94	20	M5	12,5	40	28	106,5	10	3300	1600	6,78 €
PGM94-M6	94	20	M6	12,5	40	28	106,5	9	3300	1600	6,99 €
PGM117-M5	117	25	M5	16,0	50	34	134,0	10	4400	1800	7,21 €
PGM117-M6	117	25	M6	16,0	50	34	134,0	9	4400	1800	7,63 €
PGM117-M8	117	25	M8	16,0	50	34	134,0	14	4400	1800	7,84 €
PGM120-M5	120	25	M5	16,0	50	34	134,0	10	5200	2400	7,42 €
PGM120-M6	120	25	M6	16,0	50	34	134,0	9	5200	2400	7,84 €
PGM120-M8	120	25	M8	16,0	50	34	134,0	14	5200	2400	8,05 €
PGM132-M5	132	25	M5	16,0	50	34	148,0	10	3700	2600	7,63 €
PGM132-M6	132	25	M6	16,0	50	34	148,0	9	3700	2600	8,27 €
PGM132-M8	132	25	M8	16,0	50	34	148,0	14	3700	2600	8,48 €
PGM150-M6	150	29	M6	18,0	58	40	168,0	15	5900	1900	9,02 €
PGM150-M8	150	29	M8	18,0	58	40	168,0	14	5900	1900	9,12 €
PGM150-M10	150	29	M10	18,0	58	40	168,0	14	5900	1900	9,75 €
PGM179-M8	179	29	M8	18,0	58	40	197,0	14	3800	3200	10,51 €
PGM179-M10	179	29	M10	18,0	58	40	197,0	14	3800	3200	10,81 €

Dimensions en mm

0 825 88 6000
Service 0,15 €/min
+ prix appel

cial2@hpceurope.com

HPC NOUVEAUTÉS 2017

39