


- Matière :
Inox 303
- Fonction de centrage et de serrage
- T° d'utilisation jusqu'à +430°C
- 6 Pans creux
- Résistance à la traction 550N/mm²
- Vendu par multiple, nous contacter

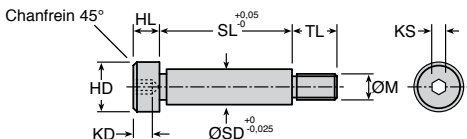

Utilisation

- Environnement difficile



REMISES

Qté	1+	6+	20+	40+	60+	100+	300+
Rem. Prix	-10%	-15%	-20%	-30%	-55%	Sur demande	

Références	Filetage		SL	HD	HL	TL	KS	KD	Stock*	Prix Uni. 1 à 5
	ØM	SD								
SHS3-4	M3	3,987	4,013	6	3	4	2,0	1,6	✓	6,39 €
SHS3-5	M3	3,987	5,013	6	3	4	2,0	1,6	✓	6,39 €
SHS3-6	M3	3,987	6,013	6	3	4	2,0	1,6	✓	6,39 €
SHS3-8	M3	3,987	8,013	6	3	4	2,0	1,6	✓	6,39 €
SHS3-10	M3	3,987	10,013	6	3	4	2,0	1,6	✓	6,39 €

*Dans la limite du disponible - Dimensions en mm

REMISES

Qté	1+	6+	20+	40+	60+	100+	300+
Rem.	Prix	-10%	-15%	-20%	-30%	-55%	Sur demande

Références	Filetage									Stock*	Prix Uni. 1 à 5
	ØM	SD	SL	HD	HL	TL	KS	KD			
SHS4-4	M4	4,987	4,013	8	4	5	2,5	2,0	✓	6,39 €	
SHS4-5	M4	4,987	5,013	8	4	5	2,5	2,0	✓	6,39 €	
SHS4-6	M4	4,987	6,013	8	4	5	2,5	2,0	✓	6,39 €	
SHS4-8	M4	4,987	8,013	8	4	5	2,5	2,0	✓	6,39 €	
SHS4-10	M4	4,987	10,013	8	4	5	2,5	2,0	✓	6,39 €	
SHS4-12	M4	4,987	12,013	8	4	5	2,5	2,0	✓	7,27 €	
SHS4-14	M4	4,987	14,013	8	4	5	2,5	2,0	✓	7,27 €	
SHS4-16	M4	4,987	16,013	8	4	5	2,5	2,0	✓	7,27 €	
SHS4-20	M4	4,987	20,013	8	4	5	2,5	2,0	✓	7,27 €	
SHS4-25	M4	4,987	25,013	8	4	5	2,5	2,0	✓	9,08 €	
SHS4-30	M4	4,987	30,013	8	4	5	2,5	2,0	✓	9,08 €	
SHS5-4	M5	5,987	4,013	10	5	6	3,0	2,4	✓	6,39 €	
SHS5-5	M5	5,987	5,013	10	5	6	3,0	2,4	✓	6,39 €	
SHS5-6	M5	5,987	6,013	10	5	6	3,0	2,4	✓	6,39 €	
SHS5-8	M5	5,987	8,013	10	5	6	3,0	2,4	✓	6,39 €	
SHS5-10	M5	5,987	10,013	10	5	6	3,0	2,4	✓	6,39 €	
SHS5-12	M5	5,987	12,013	10	5	6	3,0	2,4	✓	7,27 €	
SHS5-14	M5	5,987	14,013	10	5	6	3,0	2,4	✓	7,27 €	
SHS5-16	M5	5,987	16,013	10	5	6	3,0	2,4	✓	9,72 €	
SHS5-20	M5	5,987	20,013	10	5	6	3,0	2,4	✓	10,51 €	
SHS5-25	M5	5,987	25,013	10	5	6	3,0	2,4	✓	10,51 €	
SHS5-30	M5	5,987	30,013	10	5	6	3,0	2,4	✓	10,51 €	
SHS6-6	M6	7,987	6,013	12	6	11	4,0	3,2	✓	10,51 €	
SHS6-8	M6	7,987	8,013	12	6	11	4,0	3,2	✓	10,51 €	
SHS6-10	M6	7,987	10,013	12	6	11	4,0	3,2	✓	10,51 €	
SHS6-12	M6	7,987	12,013	12	6	11	4,0	3,2	✓	10,51 €	
SHS6-16	M6	7,987	16,013	12	6	11	4,0	3,2	✓	10,51 €	
SHS6-20	M6	7,987	20,013	12	6	11	4,0	3,2	✓	10,51 €	
SHS6-25	M6	7,987	25,013	12	6	11	4,0	3,2	✓	13,32 €	
SHS6-30	M6	7,987	30,013	12	6	11	4,0	3,2	✓	13,32 €	
SHS6.1-8/SD	M6	9,987	8,013	12	6	11	4,0	3,2	-	18,21 €	
SHS6.1-10/SD	M6	9,987	10,013	12	6	11	4,0	3,2	✓	18,21 €	
SHS6.1-12/SD	M6	9,987	12,013	12	6	11	4,0	3,2	-	18,21 €	
SHS6.1-16/SD	M6	9,987	16,013	12	6	11	4,0	3,2	-	18,21 €	
SHS8-8	M8	9,987	8,013	14	7	12	5,0	4,0	✓	13,17 €	
SHS8-10	M8	9,987	10,013	14	7	12	5,0	4,0	✓	13,17 €	
SHS8-12	M8	9,987	12,013	14	7	12	5,0	4,0	✓	13,17 €	
SHS8-16	M8	9,987	16,013	14	7	12	5,0	4,0	✓	13,17 €	
SHS8-25	M8	9,987	25,013	14	7	12	5,0	4,0	✓	18,73 €	
SHS8-30	M8	9,987	30,013	14	7	12	5,0	4,0	✓	18,73 €	
SHS10-12	M10	11,987	12,013	20	8	16	6,0	4,8	✓	22,85 €	
SHS10-16	M10	11,987	16,013	20	8	16	6,0	4,8	✓	22,85 €	
SHS10-20	M10	11,987	20,013	20	8	16	6,0	4,8	✓	22,85 €	
SHS10-25	M10	11,987	25,013	20	8	16	6,0	4,8	✓	22,85 €	
SHS10-30	M10	11,987	30,013	20	8	16	6,0	4,8	✓	36,91 €	

*Dans la limite du disponible - Dimensions en mm