


Module 1,5

Inox 304L



- Classe de précision 9
- Angle de pression 20°

Indication de couple et de puissance Pour 50 dents à 1000 t/min.				
	INOX 304L	laiton	fibre	
Nm	8,88	4,44	3,55	
kW	0,93	0,46	0,37	

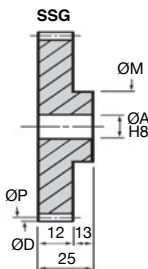

REMISES

Qté	1+	6+	20+
Rem.	Prix -12% Sur demande		

Références	Z Dents	ØP Primitif	ØD Extérieur	ØM Moyeu	ØA Alésage	Prix Uni. 1 à 5
SSG1.5-12-304L	12	18	21	14	8	28,18 €
SSG1.5-15-304L	15	22,5	25,5	18	8	30,98 €
SSG1.5-16-304L	16	24	27	20	10	32,30 €
SSG1.5-18-304L	18	27	30	20	10	36,37 €
SSG1.5-20-304L	20	30	33	20	10	38,64 €
SSG1.5-22-304L	22	33	36	20	10	42,75 €
SSG1.5-24-304L	24	36	39	25	10	44,73 €
SSG1.5-30-304L	30	45	48	25	10	56,51 €
SSG1.5-32-304L	32	48	51	25	10	60,71 €
SSG1.5-36-304L	36	54	57	30	15	69,79 €
SSG1.5-40-304L	40	60	63	40	15	74,13 €
SSG1.5-44-304L	44	66	69	40	15	74,28 €
SSG1.5-46-304L	46	69	72	40	15	77,50 €
SSG1.5-48-304L	48	72	75	40	15	80,98 €
SSG1.5-50-304L	50	75	78	40	15	112,40 €
SSG1.5-54-304L	54	81	84	40	15	112,40 €
SSG1.5-56-304L	56	84	87	40	15	112,40 €
SSG1.5-60-304L	60	90	93	40	15	154,48 €
SSG1.5-64-304L	64	96	99	40	15	154,48 €
SSG1.5-66-304L	66	99	102	40	15	177,20 €
SSG1.5-70-304L	70	105	108	40	15	177,20 €



Au choix : tout engrenage jusqu'à cette taille



SSG1.5-298-304L 298 447 450 Dimensions : contactez-nous sur demande
Dimensions en mm