
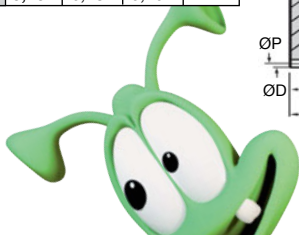


Inox 304L

Module 1,0

- Classe de précision 9
- Angle de pression 20°

Indication de couple et de puissance Pour 50 dents à 1000 t/min.			
	INOX 304L	laiton	fibre
Nm	2,600	1,250	1
kW	0,254	0,134	0,104

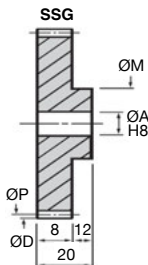

REMISES

Qté	1+	6+	20+
Rem.	Prix -12% Sur demande		

Références	Z Dents	ØP Primitif	ØD Extérieur	ØM Moyen	ØA Alésage	Prix Uni. 1 à 5
SSG1-12-304L	12	12	14	14	6	26,00 €
SSG1-15-304L	15	15	17	12	8	26,66 €
SSG1-16-304L	16	16	18	12	8	28,09 €
SSG1-18-304L	18	18	20	15	8	28,97 €
SSG1-20-304L	20	20	22	15	8	29,04 €
SSG1-22-304L	22	22	24	15	8	30,18 €
SSG1-24-304L	24	24	26	15	8	30,30 €
SSG1-25-304L	25	25	27	15	8	30,98 €
SSG1-26-304L	26	26	28	15	8	32,30 €
SSG1-28-304L	28	28	30	15	8	33,59 €
SSG1-30-304L	30	30	32	20	8	31,41 €
SSG1-32-304L	32	32	34	20	8	37,18 €
SSG1-36-304L	36	36	38	20	8	41,96 €
SSG1-40-304L	40	40	42	20	8	45,53 €
SSG1-44-304L	44	44	46	20	8	48,88 €
SSG1-48-304L	48	48	50	20	8	52,05 €
SSG1-50-304L	50	50	52	30	10	55,70 €
SSG1-54-304L	54	54	56	30	10	60,62 €
SSG1-56-304L	56	56	58	30	10	61,69 €
SSG1-60-304L	60	60	62	30	10	69,60 €
SSG1-64-304L	64	64	66	30	10	76,93 €
SSG1-66-304L	66	66	68	30	10	88,39 €
SSG1-70-304L	70	70	72	30	10	93,06 €

↓
Au choix : tout engrenage jusqu'à cette taille
↓

Dimensions en mm

0 825 88 6000
Service 0,15 € / min
+ prix appel

cial2@hpceurope.com

HPC

Tome 4 2016

4 245