
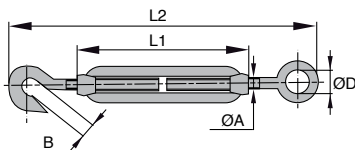
 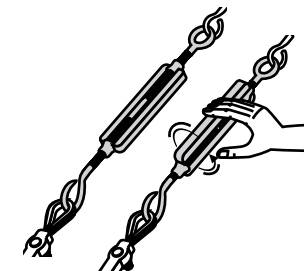


- **Ridoir à anneau et crochet**
- Accessoire d'accastillage
- Matière : inox 316

Info.

- CMU : Charge Maximale Utile
La charge de rupture est obtenue en multipliant la CMA par le coefficient de sécurité 3



REMISES

Qté	1+	20+	40+	60+
Rem. Prix	-5%	-10%	Sur demande	

Références	ØA	B	ØD	L1	L2	CMU (kg)	Poids (kg)	Stock*	Prix Uni. 1 à 19
TAC1-05/SS	M5	9	8,3	71	122-179	180	0,046	✓	8,68 €
TAC1-06/SS	M6	9,5	10,0	90	160-228	360	0,076	✓	10,38 €
TAC1-08/SS	M8	11	12,0	120	210-303	650	0,165	✓	17,95 €
TAC1-10/SS	M10	13	15,8	150	255-376	1000	0,285	✓	22,91 €
TAC1-12/SS	M12	16,8	20,0	200	305-473	1400	0,515	-	35,10 €
TAC1-16/SS	M16	16,3	26,0	245	400-593	2300	1,110	-	71,16 €

*Dans la limite du disponible - Dimensions en mm