


- Tige fileté courte
- Matière :
Acier classe 4.6 zingué

 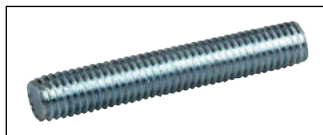


Info.

- Autres longueurs sur demande

Accessoires

- Écrous SHN
(tome 1 p.565)
- Manchon MCL et MHX
(tome 1 p.520-524)



REMISES

Qté	1+	5+	15+
Rem.	Prix -5% Sur demande		


Références	ØF	L	Qté par lot	Prix Uni. 1 à 4
TIF6-30/B	M6	30	200	21,70 €
TIF6-40/B	M6	40	200	26,11 €
TIF6-50/B	M6	50	200	29,68 €
TIF6-60/B	M6	60	200	38,55 €
TIF6-70/B	M6	70	200	42,12 €
TIF6-80/B	M6	80	200	44,81 €
TIF6-100/B	M6	100	200	55,46 €
TIF6-120/B	M6	120	200	64,35 €
TIF8-30/B	M8	30	200	29,68 €
TIF8-40/B	M8	40	200	35,92 €
TIF8-50/B	M8	50	200	40,33 €
TIF8-60/B	M8	60	200	49,22 €
TIF8-70/B	M8	70	200	53,70 €
TIF8-80/B	M8	80	200	59,02 €
TIF8-100/B	M8	100	200	67,93 €
TIF8-120/B	M8	120	200	90,10 €
TIF8-140/B	M8	140	200	114,11 €
TIF10-30/B	M10	30	100	23,71 €
TIF10-40/B	M10	40	100	25,94 €
TIF10-50/B	M10	50	100	28,61 €
TIF10-60/B	M10	60	100	33,96 €
TIF10-70/B	M10	70	100	41,47 €
TIF10-80/B	M10	80	100	44,60 €
TIF10-100/B	M10	100	100	54,36 €
TIF10-120/B	M10	120	100	72,13 €
TIF10-140/B	M10	140	100	81,91 €
TIF10-160/B	M10	160	100	93,46 €
TIF12-40/B	M12	40	100	33,05 €
TIF12-50/B	M12	50	100	39,27 €
TIF12-60/B	M12	60	100	46,80 €
TIF12-70/B	M12	70	100	55,26 €
TIF12-80/B	M12	80	100	65,05 €
TIF12-100/B	M12	100	100	76,59 €
TIF12-120/B	M12	120	100	103,23 €
TIF12-140/B	M12	140	100	118,77 €
TIF12-160/B	M12	160	100	136,11 €

Dimensions en mm

- Tige fileté courte

- Matière :

 inox 304



REMISES

Qté	1+	5+	10+
Rem. Prix	-5% Sur demande		

Références	ØF	L	Qté par lot	Prix Uni. 1 à 4
TIF6-30/SS/B	M6	30	100	55,70 €
TIF6-40/SS/B	M6	40	100	57,05 €
TIF6-50/SS/B	M6	50	100	61,91 €
TIF6-60/SS/B	M6	60	100	68,58 €
TIF6-70/SS/B	M6	70	100	75,71 €
TIF6-80/SS/B	M6	80	100	81,91 €
TIF6-100/SS/B	M6	100	100	95,25 €
TIF6-120/SS/B	M6	120	100	108,58 €
TIF8-30/SS/B	M8	30	100	58,37 €
TIF8-40/SS/B	M8	40	100	68,58 €
TIF8-50/SS/B	M8	50	100	79,26 €
TIF8-60/SS/B	M8	60	100	94,80 €
TIF8-70/SS/B	M8	70	100	109,89 €
TIF8-80/SS/B	M8	80	100	125,01 €
TIF8-100/SS/B	M8	100	100	137,44 €
TIF8-120/SS/B	M8	120	100	152,55 €
TIF8-140/SS/B	M8	140	100	174,31 €
TIF10-30/SS/B	M10	30	100	83,24 €
TIF10-40/SS/B	M10	40	100	100,58 €
TIF10-50/SS/B	M10	50	100	117,89 €
TIF10-60/SS/B	M10	60	100	133,89 €
TIF10-70/SS/B	M10	70	100	146,33 €
TIF10-80/SS/B	M10	80	100	161,43 €
TIF10-100/SS/B	M10	100	100	192,08 €
TIF10-120/SS/B	M10	120	100	223,18 €
TIF10-140/SS/B	M10	140	100	257,85 €
TIF10-160/SS/B	M10	160	100	293,39 €
TIF12-40/SS/B	M12	40	100	153,43 €
TIF12-50/SS/B	M12	50	100	186,30 €
TIF12-60/SS/B	M12	60	100	213,86 €
TIF12-80/SS/B	M12	80	100	271,16 €
TIF12-100/SS/B	M12	100	100	324,91 €
TIF12-120/SS/B	M12	120	100	381,35 €
TIF12-140/SS/B	M12	140	100	438,63 €
TIF12-160/SS/B	M12	160	100	508,38 €

Dimensions en mm

Tél/ 0 825 88 5000
Service 0,15 € / min
+ prix appel