



Tête orientable longue


Inox

TOL

- Pour guide latéral
- Matières :
Tête : inox (304)
Ecrrou et rondelle : inox



Exemple d'application

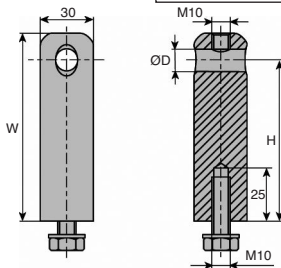

REMISES

Qté	1+	10+	20+
Rem. Prix	-5%	Sur demande	

Références	ØD	Pour Axe	H	W	Masse (kg)	Prix Uni. 1 à 9
TOL12-40/SS	12,5	APB12	40	55	0,28	27,49 €
TOL12-60/SS	12,5	APB12	60	75	0,38	33,58 €
TOL12-90/SS	12,5	APB12	90	105	0,55	36,86 €
TOL12-130/SS	12,5	APB12	130	145	0,77	49,17 €
TOL14-40/SS	14,5	APB14	40	56	0,28	27,49 €
TOL14-60/SS	14,5	APB14	60	76	0,38	31,79 €
TOL14-90/SS	14,5	APB14	90	106	0,55	35,10 €
TOL14-130/SS	14,5	APB14	130	146	0,77	49,17 €
TOL16-40/SS	16,5	APB16	40	57	0,28	27,49 €
TOL16-60/SS	16,5	APB16	60	77	0,38	33,58 €
TOL16-90/SS	16,5	APB16	90	107	0,55	36,86 €
TOL16-130/SS	16,5	APB16	130	147	0,77	49,17 €