
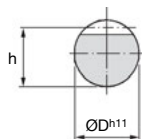
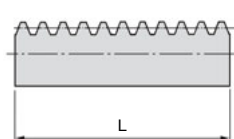


- Angle de pression 20°
- Diamètre tolérance h11
- Matière :
Acier étiré A60

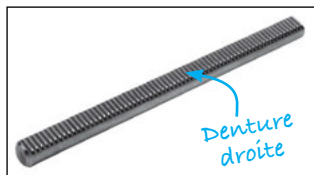

REMISES

Qté	1+	6+	20+
Rem.	Prix -12% Sur demande		

Références	Module	h (mm)	ØD (mm)	L (mm)	Stock*	Prix Uni. 1 à 5
TRM1-1000	1	9,00	10	999	✓	99,27 €
TRM1.5-1000	1,5	13,50	15	999	✓	145,73 €
TRM2-1000	2	18,00	20	999	✓	142,52 €
TRM2.5-1000	2,5	22,50	25	997	✓	180,97 €
TRM3-1000	3	27,00	30	999	✓	183,36 €
TRM4-1000	4	36,00	40	1005	✓	228,20 €
TRM5-1000	5	45,00	50	1005	-	285,93 €
TRM6-1000	6	54,00	60	999	-	385,26 €

*Dans la limite du disponible - Dimensions en mm