


# Vis tête hexagonale **DIN 933**

## VTH

## Acier zingué classe 8.8

- Vis selon DIN 933
- Filetage total
- Matière :  
Acier zingué classe 8.8
- Caractéristiques mécaniques conformes  
à la norme ISO898-1
- Conditionnées par lot

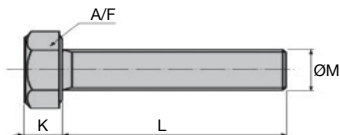

### REMISES

Qté	1+	6+	20+	50+
Rem. Prix		-5%	-20%	Sur demande

Références	ØM	Pas		K	A/F surplats	Qté/lot	Prix Uni.
		P	L				1 à 5
VTH4-10/B	M4	0,70	10	2,92	7,0	500	11,44 €
VTH4-12/B	M4	0,70	12	2,92	7,0	500	12,61 €
VTH4-16/B	M4	0,70	16	2,92	7,0	500	14,89 €
VTH4-20/B	M4	0,70	20	2,92	7,0	500	16,81 €
VTH4-25/B	M4	0,70	25	2,92	7,0	500	19,84 €
VTH4-30/B	M4	0,70	30	2,92	7,0	500	22,51 €
VTH4-35/B	M4	0,70	35	2,92	7,0	200	14,05 €
VTH4-40/B	M4	0,70	40	2,92	7,0	200	15,74 €
VTH5-10/B	M5	0,80	10	3,65	8,0	500	11,60 €
VTH5-12/B	M5	0,80	12	3,65	8,0	500	12,82 €
VTH5-16/B	M5	0,80	16	3,65	8,0	500	14,95 €
VTH5-20/B	M5	0,80	20	3,65	8,0	500	17,12 €
VTH5-25/B	M5	0,80	25	3,65	8,0	500	19,84 €
VTH5-30/B	M5	0,80	30	3,65	8,0	500	22,60 €
VTH5-35/B	M5	0,80	35	3,65	8,0	200	10,16 €
VTH5-40/B	M5	0,80	40	3,65	8,0	200	11,23 €
VTH5-45/B	M5	0,80	45	3,65	8,0	200	15,43 €
VTH5-50/B	M5	0,80	50	3,65	8,0	200	17,09 €

Dimensions en mm



## REMISES

Qté	1+	6+	20+	50+
Rem. Prix	-5%	-20%	Sur demande	

Références	ØM	Pas P	L	K	A/F surplats	Qté/lot	Prix Uni. 1 à 5
VTH6-10/B	M6	1,00	10	4,15	10,0	500	22,51 €
VTH6-16/B	M6	1,00	16	4,15	10,0	500	18,97 €
VTH6-20/B	M6	1,00	20	4,15	10,0	500	21,39 €
VTH6-25/B	M6	1,00	25	4,15	10,0	500	24,58 €
VTH6-30/B	M6	1,00	30	4,15	10,0	500	27,78 €
VTH6-40/B	M6	1,00	40	4,15	10,0	200	13,70 €
VTH6-50/B	M6	1,00	50	4,15	10,0	200	16,27 €
VTH6-60/B	M6	1,00	60	4,15	10,0	200	21,51 €
VTH8-20/B	M8	1,25	20	5,45	13,0	200	17,34 €
VTH8-30/B	M8	1,25	30	5,45	13,0	200	21,82 €
VTH8-40/B	M8	1,25	40	5,45	13,0	100	13,20 €
VTH8-50/B	M8	1,25	50	5,45	13,0	100	15,34 €
VTH8-60/B	M8	1,25	60	5,45	13,0	100	17,65 €
VTH8-70/B	M8	1,25	70	5,45	13,0	100	19,88 €
VTH8-80/B	M8	1,25	80	5,45	13,0	100	22,14 €
VTH10-20/B	M10	1,50	20	6,58	17,0	200	29,94 €
VTH10-30/B	M10	1,50	30	6,58	17,0	200	37,01 €
VTH10-40/B	M10	1,50	40	6,58	17,0	100	21,98 €
VTH10-50/B	M10	1,50	50	6,58	17,0	100	25,50 €
VTH10-60/B	M10	1,50	60	6,58	17,0	50	14,58 €
VTH10-70/B	M10	1,50	70	6,58	17,0	50	16,33 €
VTH10-80/B	M10	1,50	80	6,58	17,0	50	18,09 €
VTH10-100/B	M10	1,50	100	6,58	17,0	50	21,61 €
VTH12-20/B	M12	1,75	20	7,68	19,0	100	21,85 €
VTH12-35/B	M12	1,75	35	7,68	19,0	100	29,13 €
VTH12-45/B	M12	1,75	45	7,68	19,0	100	34,22 €
VTH12-55/B	M12	1,75	55	7,68	19,0	50	19,60 €
VTH12-60/B	M12	1,75	60	7,68	19,0	50	20,53 €
VTH12-70/B	M12	1,75	70	7,68	19,0	50	23,43 €
VTH12-80/B	M12	1,75	80	7,68	19,0	50	25,96 €
VTH12-100/B	M12	1,75	100	7,68	19,0	50	31,05 €

Dimensions en mm

**0 825 88 6000**  
 Service 0,15 € / min  
 + prix appel

Fax

[cial2@hpceurope.com](mailto:cial2@hpceurope.com)

HPC

Tome ① 2016

① 419