


# Bouton moleté femelle




## 712

## Taraudage M4 à M6

- **Élément de manœuvre**
- Insert : laiton
- T° d'utilisation : -30°C à +140°C
- Matière :  
Plastique phénolique noir

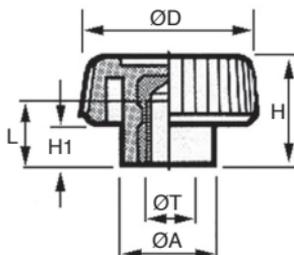

Type 1

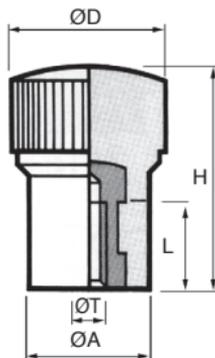

Type 4

### REMISES

Qté	1+	10+	20+	50+	100+
Rem. Prix	-20%	-30%	-40%	Sur demande	

Références	Taraudage			H1	L	ØA	Stock*	Prix Uni.
	ØT	ØD	H					1 à 9
<b>TYPE 1</b>								
712-019	M6	23	14	5,50	10	12	✓	3,91 €
<b>TYPE 4</b>								
712-031	M4	12	14	-	10	10	✓	3,87 €
712-032	M5	15	16	-	10	12	✓	5,30 €
712-033	M6	17	22	-	9	12	✓	6,06 €

\*Dans la limite du disponible - Dimensions en mm