

# Bague d'arrêt plastique



## BAP







## Ø10 à Ø20, 2 éléments

- Bague d'arrêt 2 éléments

- Matières :

Corps : polyamide renforcé

Visserie : inox 304

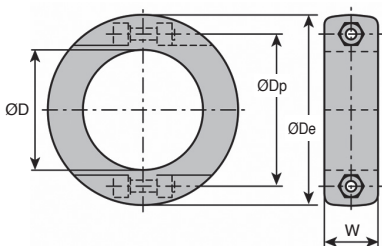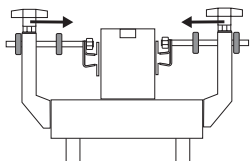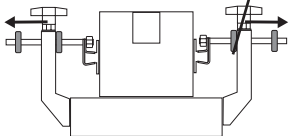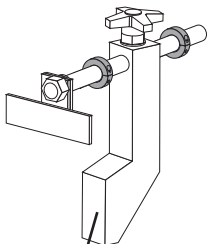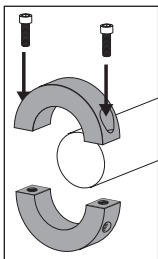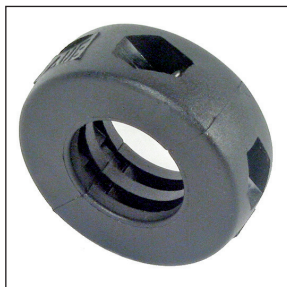




### REMISES

Qté	1+	40+	100+	200+	300+
Rem. Prix	-5%	-10%	-15%	Sur demande	

Références	ØD	ØDe	ØDp	W	Masse (kg)	Stock*	Prix Uni. 1 à 39
BAP-10	10	30	20	12	0,01	✓	3,75 €
BAP-12	12	30	20	12	0,01	✓	3,75 €
BAP-14	14	30	20	12	0,01	✓	3,75 €
BAP-15	15	39	27	14	0,02	✓	3,75 €
BAP-16	16	39	27	14	0,02	✓	3,75 €
BAP-18	18	39	27	14	0,02	✓	3,75 €
BAP-20	20	40	29	14	0,02	✓	3,81 €

\*Dans la limite du disponible - Dimensions en mm

- Bague d'arrêt 2 éléments
- Alésage lisse ou rainuré
- Matières :  
Corps : polyamide renforcé  
Visserie : inox 304

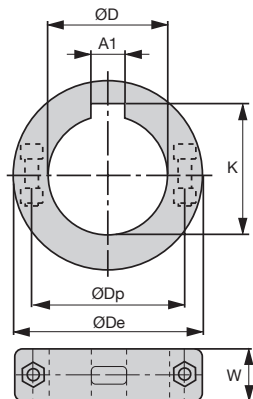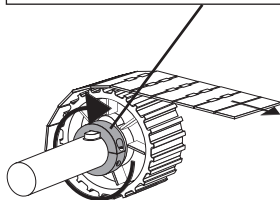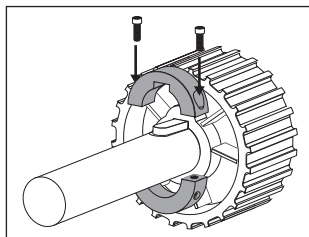

## REMISES

Qté	1+	40+	100+	200+	300+
Rem. Prix		-5%	-10%	-15%	Sur demande

Références		ØD	A1	ØDe	ØDp	W	K	Masse (kg)	Stock*	Prix Uni. 1 à 39		
Lisse	Rainuré									Lisse	Lisse	Rainuré
BAP-25	BAP-25K	25	8	45	35	14	28,3	0,02	✓	3,81 €	6,79 €	6,79 €
BAP-30	BAP-30K	30	8	55	45	16	33,3	0,03	✓	4,56 €	7,41 €	7,41 €
BAP-35	BAP-35K	35	10	60	47	16	38,3	0,03	✓	4,48 €	7,80 €	7,80 €
BAP-40	BAP-40K	40	12	64	51	18	43,3	0,04	✓	4,94 €	7,83 €	7,83 €

\*Dans la limite du disponible - Dimensions en mm